

Universal Restraint Clip, Slotted



认证



功能

Slotted design ideal for attaching to existing threaded rod on trapezes

Meets CEN/TS 17551:2021 requirements for Seismic Sway Bracing

技术参数

完成: 电镀锌

材料: 钢

Table 1/1

物料号	订货号	支架尺寸	杆尺寸 (RS)	厚度 (T)
CSBURCR58	402203	#12, #18	16	4.27 mm
CSBURCR38	402201	#12, #18	10	4.27 mm


物料号	订货号	支架尺寸	杆尺寸 (RS)	厚度 (T)
CSBURCR12	402202	#12, #18	12	4.27 mm

其他产品详情

Brace member is not included.

UL Loads		
Part Number	Brace Member	Load Rating
CSBURCR38	CSB12CBL	1859 N
	CSB18CBL	3434 N
CSBURCR12	CSB12CBL	1859 N
	CSB18CBL	3434 N
CSBURCR58	CSB12CBL	1859 N
	CSB18CBL	3434 N

图

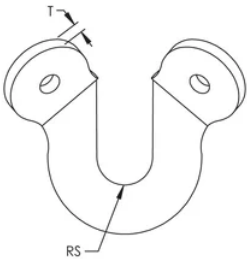

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

