

Universal Structural Attachment



认证



功能

Universal design allows one product to attach directly to concrete, wood, bar joist or I-beam adapters

Snap-off bolt head helps enable easy installation and inspection of seismic sway braces

Use for both lateral and longitudinal sway brace applications

Works with 1" through 2" brace pipes and 1/4" angle iron braces to reduce inventory

Center bolt does not require tightening

Meets NFPA®-13 requirements for seismic sway bracing

Meets CEN/TS 17551:2021 requirements for Seismic Sway Bracing

技术参数

Table 1/2


物料号	订货号	材料	完成	孔尺寸 (HS)	A	B
-----	-----	----	----	----------	---	---

CSBUNIV050EG	404407	铸铁	电镀锌	14 mm	133.4 mm	101.6 mm
CSBUNIV075EG	404409	铸铁	电镀锌	21 mm	133.4 mm	101.6 mm

Table 2/2			
物料号	订货号	C	认证
CSBUNIV050EG	404407	41.4 mm	UL, FM Approved, Seismic, AON Fire Protection, Rigid Seismic, Korea Fire Institute, Rigid Seismic, KOR, OSHPD, cUL
CSBUNIV075EG	404409	41.4 mm	cUL, AON Fire Protection, Rigid Seismic, UL, FM Approved, Seismic, OSHPD

UL Loads		
Part number	Brace Member	Rating
CSBUNIV050EG	25 mm - 50 mm EN10255H	6094 N
CSBUNIV075EG	25 mm - 50 mm EN10255H	8896 N

FM Loads					
Brace Type	Service Pipe Size	Horizontal Capacity per Installation Angle from Vertical			
		30°- 44°	45°- 59°	60°- 74°	75°- 90°
Pipe	N/A	7,205 N	10,230 N	12,545 N	13,965 N

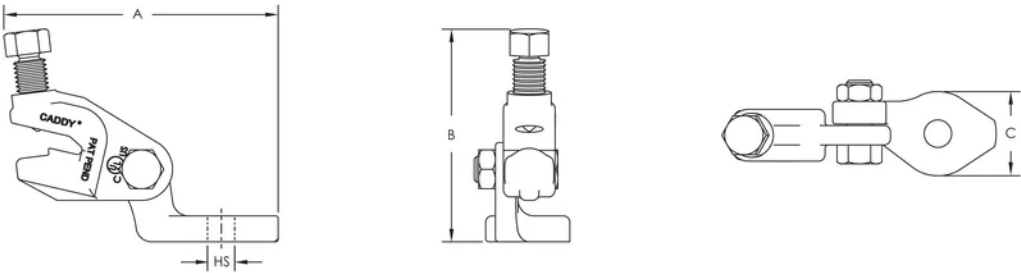

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

