

Branch Line Restraint Pipe Attachment

Data Solutions



认证



功能

Accepts 3/8" or 1/2" (M10 or M12) threaded rod

Quick grip clamp simplifies measuring and cutting of threaded rod

Eliminates need to cut threaded rod to exact dimensions

Works with rough-cut threaded rod and eliminates pipe-side deburring

Can be installed with threaded rod above or below the service pipe

Shear-off head helps ensure correct torque and simplifies inspection

技术参数


完成: 电镀锌

材料: 钢

Table 1/2						
物料号	订货号	NB/DN	外径 (OD)	杆尺寸 (RS)	高度 (H)	长度 (L)
CSBBRP0200E G	404480	50	60.3mm	10, 12	100.3mm	68.3mm
CSBBRP0125E G	404478	32	42.2mm	10, 12	82.6mm	50mm
CSBBRP0150E G	404479	40	48.3mm	10, 12	88.9mm	56.1mm
CSBBRP0100E G	404477	25	33.4mm	10, 12	73.7mm	41.4mm

Table 2/2		
物料号	订货号	宽度 (W)
CSBBRP0200EG	404480	22.2mm
CSBBRP0125EG	404478	22.2mm
CSBBRP0150EG	404479	22.2mm
CSBBRP0100EG	404477	22.2mm

图

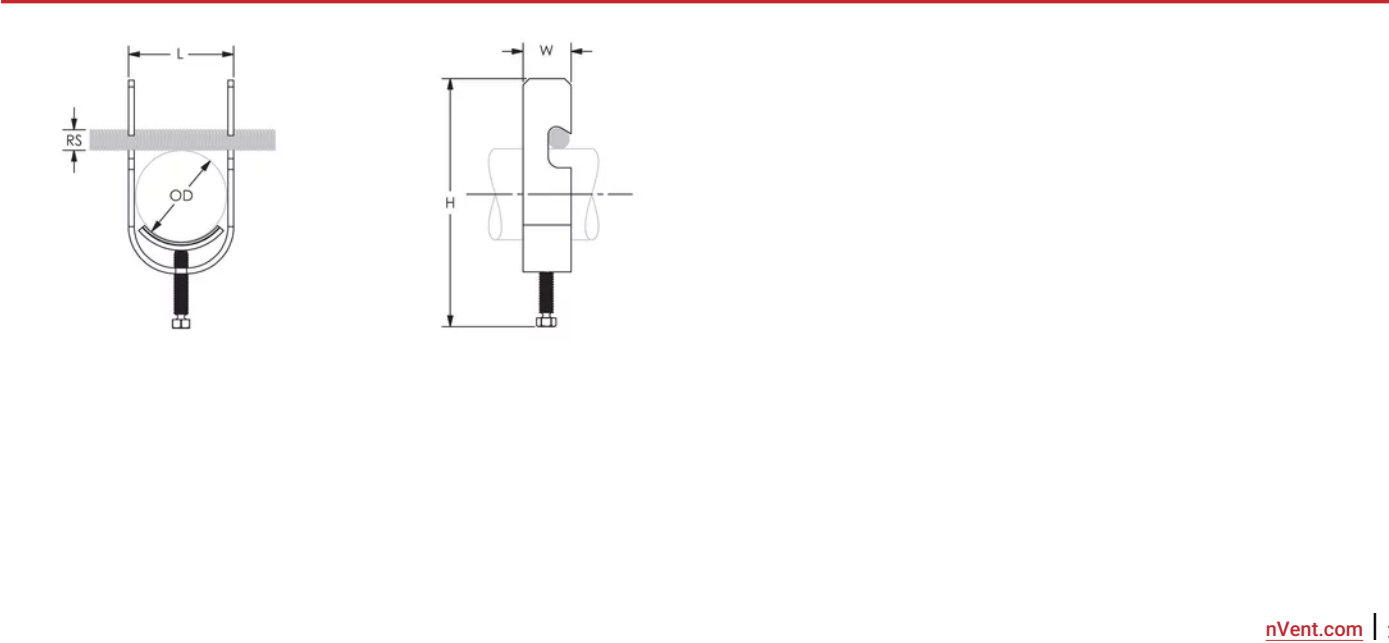

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE