

Branch Line Restraint Structure Attachment to Steel

Data Solutions



认证



功能

Swivel barrel nut accepts 3/8" or 1/2" (M10 or M12) threaded rod

Attaches to steel members with self-drilling/tapping screw

技术参数

完成: 电镀锌

材料: 钢

Table 1/2

物料号	订货号	杆尺寸 (RS)	法兰厚度 (FT)	高度 (H)	长度 (L)	宽度 (W)
-----	-----	----------	-----------	--------	--------	--------


CSBBRS1EG		0.375, 0.5	2.7 – 12.7mm	28.2mm	40.4mm	26.9mm
CSBBRS1MEG	402239	10, 12	2.7 – 12.7mm	28.2mm	40.4mm	26.9mm

Table 2/2				
物料号	订货号	螺钉直径 (Sc)	螺钉长度 (L)	认证
CSBBRS1EG		2.7mm	32mm	OSHDP, FM Approved, Seismic, UL
CSBBRS1MEG	402239	2.7mm	32mm	FM Approved, Seismic, UL, AON Fire Protection, Rigid Seismic

其他产品详情

Branch line structural attachments are for restraint only and not for the hanging of fire sprinkler piping.

图

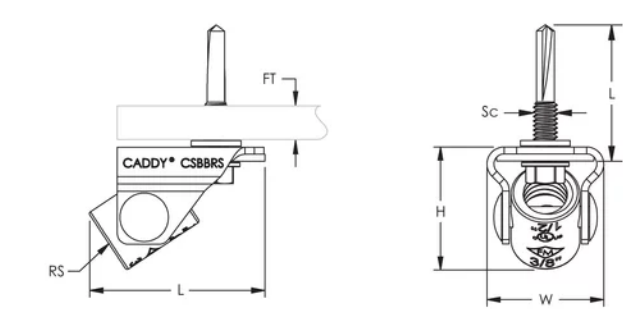

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE