 


Disconnecting Link with Enclosure for Cable



功能

Allows for quick and easy disconnection of the earthing system to facilitate testing of the earth in isolation

High conductivity, hard drawn, electrolytic tough pitch copper per EN 13601

Includes stainless steel 304 enclosure, rubber dustproof, halogen-free polyamide insulators, stainless steel hardware

Compression straight lug: according to DIN46235 standard

Rubber gland for cable connection

8 microns tinned finish according to ASTM B545 Service Class “C”

技术参数

Table 1/3

物料号	材料	完成	A	直径 (Ø)	高度 (H)	厚度 (T)
DLCBX95	不锈钢 304 (EN 1.4301), Copper	裸露	90 mm	20 mm	66.5 mm	4 mm
DLTBX95	Stainless Steel 304 (EN 1.4301), 镀锡铜	镀锡	90 mm	20 mm	66.5 mm	4 mm

Table 2/3

物料号	螺纹尺寸 (TS)	长度 1 (L1)	长度 2 (L2)	长度 3 (L3)	长度 4 (L4)	宽度 1 (W1)
DLCBX95	M8	125 mm	230 mm	210mm	160 mm	40 mm


物料号	螺纹尺寸 (TS)	长度 1 (L1)	长度 2 (L2)	长度 3 (L3)	长度 4 (L4)	宽度 1 (W1)
DLTBX95	M8	125 mm	230 mm	210mm	160 mm	40 mm

Table 3/3			
物料号	宽度 2 (W2)	宽度 3 (W3)	单位重量
DLCBX95	150 mm	170mm	1.45 kg
DLTBX95	150 mm	170mm	1.45 kg

其他产品详情

Available cable size ≤ 95 mm².

图

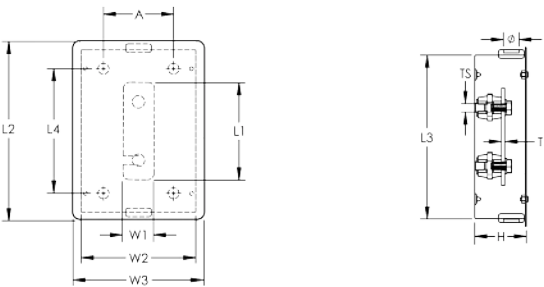

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE