


Aluminium Terminal Box, HALP

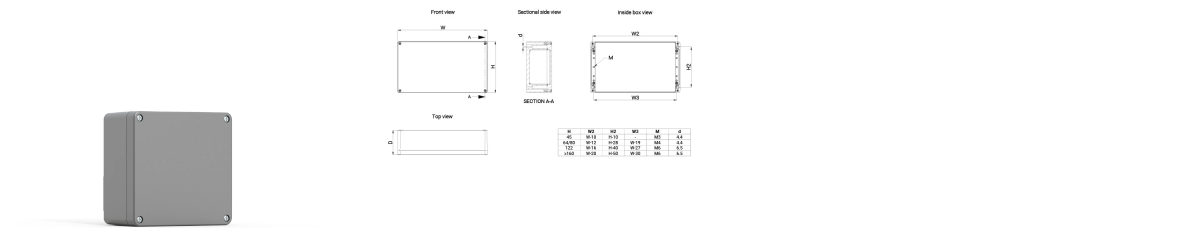

The aluminium terminal box range, HALP, with a IP 66, 67 protection degree, is available off the shelf in many different sizes. The HALP range is well suited for indoor and outdoor environments thanks to excellent corrosion resistance. Water and dust are prevented from entering the terminal box, thus eliminating the risk for component failure, and with that, unnecessary downtime.

工业标准

CE UKCA

EAC

GOST

IP

功能

Material: Aluminium alloy EN AC-47100.

Gasket: Standard supply fitted with a polyurethane gasket. Silicone, neoprene and EPDM gaskets are available on request.

Temperature resistance: -30 °C to +80 °C.

Protection: IP 66, 67, IK 09, 08 for HALP050503GE.

Finish: RAL 7001.

Approvals: CE, GOST. For cULus_UL Listed approvals, please contact our sales department.

Delivery: Body and cover are manufactured from aluminum, cover screws are made of stainless steel.


技术参数

材料： 铝
完成： 粉末涂层
颜色代码： RAL 7001
颜色： 银灰色

Table 1/1						
物料号	高度 (H)	宽度 (W)	深度 (D)	主体厚度	盖板厚度	盖板螺钉数量
HALP050503GE	45mm	50mm	30mm	3mm	2mm	2
HALP080806GE	80mm	74mm	57mm	3.5mm	2.5mm	4
HALP081306GE	80mm	124mm	57mm	3.5mm	2.6mm	4
HALP081806GE	80mm	175mm	57mm	3.5mm	2.5mm	4
HALP082506GE	80mm	249mm	57mm	3.5mm	2.5mm	4
HALP060604GE	64mm	57mm	36mm	3.5mm	3mm	4
HALP061004GE	64mm	98mm	36mm	3.5mm	3mm	4
HALP061504GE	64mm	150mm	36mm	3.5mm	3mm	4
HALP121208GE	122mm	121mm	80mm	4.1mm	3.7mm	4
HALP123608GE	122mm	359mm	80mm	4.1mm	3.7mm	4
HALP161609GE	160mm	160mm	90mm	4.1mm	3.7mm	4
HALP163609GE	160mm	359mm	90mm	4.1mm	3.7mm	4
HALP233311GE	230mm	329mm	110mm	4.1mm	3.7mm	4
HALP233318GE	230mm	329mm	180mm	4.5mm	3.7mm	4
HALP234011GE	230mm	400mm	110mm	4.1mm	3.7mm	4

物料号	高度 (H)	宽度 (W)	深度 (D)	主体厚度	盖板厚度	盖板螺钉数量
HALP121209GE	122mm	121mm	90mm	4.1mm	4mm	4
HALP122208GE	122mm	219mm	80mm	4mm	4mm	4
HALP122209GE	122mm	219mm	90mm	4mm	4mm	4
HALP162609GE	160mm	260mm	90mm	4mm	4mm	4
HALP165609GE	160mm	560mm	90mm	4mm	4mm	6
HALP232011GE	230mm	199mm	110mm	4.1mm	4.1mm	4
HALP236011GE	230mm	599mm	110mm	4mm	4mm	6

图

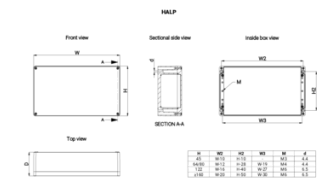

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE