


Brace Terminals, WO60

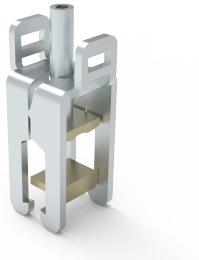

Connection terminals for cables up to 300 mm².

功能

Description: Brace terminal, up to 300mm², for round conductors. Terminal with captive clamping screws, conductor can be overlapped. Indication of nominal cross-section and tightening torque noted on the terminal.

Rated voltage: 690 V

Approvals: UL

技术参数

Table 1/1						
物料号	高度	宽度	深度	材料	完成	快速发货
01135	26mm	28mm	72mm	低碳钢	电镀	No
01318	43mm	38mm	92mm	低碳钢	电镀	No
01760	43mm	40mm	96mm	低碳钢	电镀	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE