


Busbar Adapter 32A With Cables And 1 Mounting Rail, WO60

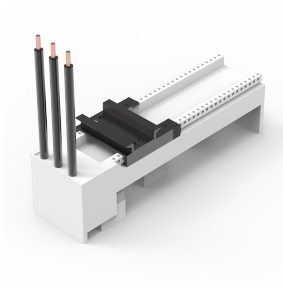

Busbar adapter with one mounting rail, pre-fitted with cables 6 mm².

工业标准

UL

CSA

GL

功能

Description: Busbar adapter 32 A. With adjustable mounting rails. With leads 6 mm².

Rated voltage: 690 V.

Rated current: 32 A.

For busbars: 12, 15, 20, 25, 30 × 5, 10.

Power dissipation at 80% load: 1.5 W.

Poles: 3-pole.

Pack quantity: 1 pc.

Approvals: CSA, UL, GL.

技术参数

Table 1/1						
物料号	高度	宽度	深度	材料	完成	颜色
32441	200mm	54mm	63mm	塑料, 低碳钢	电镀	黑色, 浅灰色
32443	200mm	63mm	63mm	塑料, 低碳钢	电镀	黑色, 浅灰色
32446	200mm	81mm	63mm	塑料, 低碳钢	电镀	黑色, 浅灰色

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE