


Busbar Adapter 32A With Cables And 2 Mounting Rails, WO60

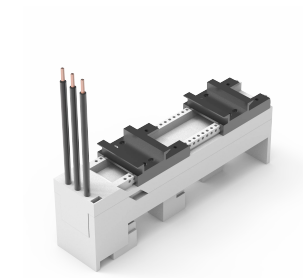

Busbar adapter 32 A. With two adjustable mounting rails. The upper section is removable and has pre-fitted cables.

工业标准

UL

CSA

GL

功能

Description: Busbar adapter 32 A. With two adjustable mounting rails. With removable upper section and leads (6 mm²).

Rated voltage: 690 V

Rated current: 32 A

For busbars: 12, 15, 20, 25, 30 × 5, 10

Power dissipation at 80% load: 2.2 W

Poles: 3-pole

Dimensions: 54 × 200 × 75 mm

Pack quantity: 1 pc.

Approvals: CSA, UL, GL

技术参数

Table 1/1						
物料号	高度	宽度	深度	材料	完成	颜色
32404	54mm	200mm	75mm	塑料, 低碳钢	电镀	黑色, 浅灰色

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE