


Busbar adapter 32A Without Cables, WO60

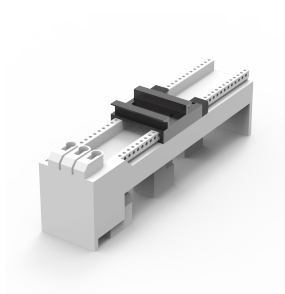

Universal busbar adapter, with one adjustable mounting rail and with spring terminals 1.5-6 mm².

功能

Description: Busbar adapter 32 A. With one adjustable mounting rail. Without cables, with spring terminals 1.5 - 6 mm².

Rated voltage: 690 V

Rated current: 32 A

For busbars: 12, 15, 20, 25, 30 × 5, 10

Power dissipation at 80% load: 1.6 W

Poles: 3-pole

Pack quantity: 1 pcs.

技术参数

Table 1/1						
物料号	高度	宽度	深度	材料	完成	颜色
32486	200mm	45mm	63mm	塑料, 低碳钢	电镀	黑色, 浅灰色

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE