


Busbar Adapter 80A Without Cables, WO60

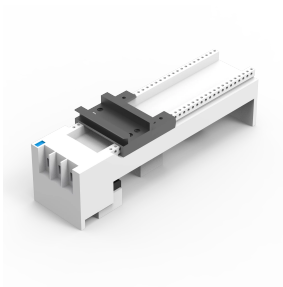

Busbar adapter with one mounting rail with screw terminals 16 mm².

工业标准

UL

CSA

GL

功能

Approvals: CSA, UL, GL

Poles: 3-pole

Power dissipation at 80% load: 6 W

For busbars: 12, 15, 20, 25, 30 × 5, 10

Rated current: 80 A

Rated voltage: 690 V

Pack quantity: 1 pc.

Description: Busbar adapter 80 A. With one adjustable mounting rail. With terminals 16 mm², operated from the back.

技术参数

Table 1/1						
物料号	高度	宽度	深度	材料	完成	颜色
32466	200mm	54mm	63mm	塑料, 低碳钢	电镀	黑色, 浅灰色
32469	200mm	72mm	63mm	塑料, 低碳钢	电镀	黑色, 浅灰色

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE