


分配器安装进线口进线盖板，CCFD

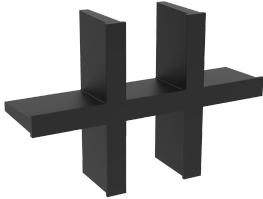

With the click-in CCFD inlays, dimensioning of the frame opening can be adjusted based on the grommet being used.

工业标准

UL 508A Component Recognized; Type 1, 12, 4X (indoor only);

File No. E61997

UL94 V-0 Flammability

NEMA Type 1, 12, 4X (indoor only)

CE

IP66

功能

Description: With the CCFD click-in inlays, dimensioning of the frame opening can be adjusted based on to the grommet being used. An audible click confirms correct installation. This flexible cable entry configuration enables you to accommodate various requirements for cables, lines, tubing, pneumatic and hydraulic lines.

Finish: Black

Flammability: UL94 V-0

Material: Polyamide 6.6 / TPE

Pack quantity: 5pcs

Protection: IP66, NEMA 1, 4x, 12 (Indoor use only)

Temperature resistance: -40°C to +90°C

技术参数

Table 1/1						
物料号	订货号	高度	宽度	深度	材料	完成
CCFD1	58331	5mm	45mm	17.7mm	塑料	未处理
CCFD2	58332	25mm	45mm	17.7mm	塑料	未处理
CCFD4	58333	45mm	45mm	17.7mm	塑料	未处理
CCFD6	58334	70mm	45mm	17.7mm	塑料	未处理

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE