


## 安装轨，螺钉固定式，CLPK

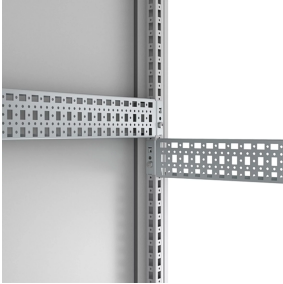

通过使用这些安装轨，可以快速轻松地将其他附件和电气设备安装在所需位置。

### 功能

Description: Universal profile for both depth and width fitting on the 25 mm DIN hole pattern of the enclosure's frame or in combination with the CLPF and VB profiles. The 75 mm wide profile is equipped with three rows of holes of which one is turned 90°. This makes it possible to mount the CLPF profiles in both directions. The CLPK can be secured by the use of self tapping screws.

Material: 1.5 mm zinc plated steel.

Pack quantity: 4 profiles.

技术参数

厚度: 1.5mm  
材料: 低碳钢  
完成: 镀锌

Table 1/1						
物料号	订货号	高度	宽度	深度	额定负载	外壳材料
CLPK1000	CLPK1000	74mm	1000mm	26mm	1200N	低碳钢
CLPK1200	CLPK1200	74mm	1200mm	26mm	1200N	低碳钢
CLPK300		74mm	300mm	26mm	2000N	低碳钢
CLPK400	CLPK400	74mm	400mm	26mm	2000N	低碳钢
CLPK500	CLPK500	74mm	500mm	26mm	2000N	低碳钢
CLPK600	CLPK600	74mm	600mm	26mm	1600N	低碳钢
CLPK800	CLPK800	74mm	800mm	26mm	1600N	低碳钢

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**