


Compact Heater With / Without Thermostat, ECH(T)

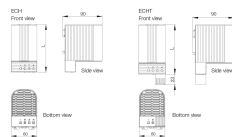

This double insulated compact heater, ECH(T) is available with or without a thermostat. Water condensation is eliminated, also when the ambient temperature drops sharply. Choosing a version with an already integrated thermostat will save space inside the enclosure and reduce installation time compared with a thermostat mounted separately.

工业标准

cRUus_UL Recognized

CE

EAC

功能

Description: Double insulated vertical heater to prevent condensation. Mounting clip for 35 mm DIN rail (EN60715).

Touch-safe heater, the temperatures of the housing are kept under 80 °C except upper protective grille. The heater with thermostat (ECHT) includes a plug-in thermostat therefore it does not require additional wiring, starting temperature of 5 °C, and switch-off temperature of 15 °C.

Heating element: PTC resistor, temperature limiting.

Material: Plastic according to UL94 V-0.

Operating temperature: -45 °C to +70 °C. The heating capacity is for ambient temperature 20 °C.

Connection: Pole terminal 2.5 mm², torque 0.8 Nm max.

Protection: IP 20, Class II (double insulated).

Approvals: CE, EAC.

Finish: Black.

Pack quantity: 1 piece.

技术参数

Table 1/1						
物料号	高度	宽度	深度	材料	完成	颜色
ECHT50	110mm	60mm	90mm	塑料	纹理	黑色
ECH50	110mm	60mm	90mm	塑料	纹理	黑色
ECH100	110mm	60mm	90mm	塑料	纹理	黑色
ECHT100	110mm	60mm	90mm	塑料	纹理	黑色
ECH150	150mm	60mm	90mm	塑料	纹理	黑色
ECHT150	150mm	60mm	90mm	塑料	纹理	黑色

其他产品详情

Voltage range: min. 110V - max 265 V. Operating below 140 V AC reduces performance by approx. 10%

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE