


Compact Single Wall Version Aluminum Single And Multiple Doors, EKOM-SW

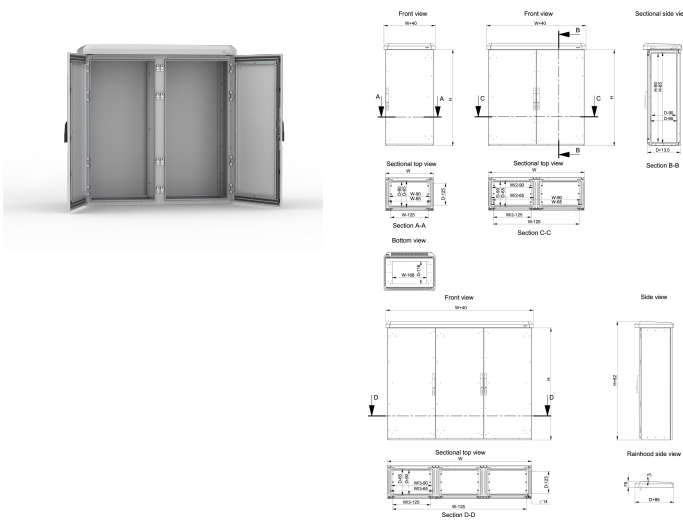

The aluminium single wall compact floor standing enclosure range, EKOM-SW, with a IP 66 protection degree for outdoor use, is available off the shelf in many different sizes. Components inside the enclosure are well protected through the high protection degree, but also by anti-vandalism features and high thermal management efficiency. These factors all contribute to eliminate the risk for component failure, and with that, unnecessary downtime.

工业标准

cULus_UL Listed

CE, UK CA, UL, EAC

IP

功能

Body: One piece enclosure body. Integrated depth profiles with hole pattern, allowing mounting plate adjustable in depth. The frame in multiple door versions, is divided into individual modules by means of vertical dividers.

Rainhood: Sloped rainhood with integrated rain gutter and ventilation channels in the perimeter.

Earthing: All panels are earthed through their fittings and are equipped with a separate earthing stud.

"Approvals: Climatic and Chemically active substances resistance according to EN61969-3 "Mechanical structures for electronic equipment. Outdoor enclosures" ."

Bottom plates: Supplied as accessory.

Rear panel: Fastened from the inside. Standard facilities for rear door mounting.

Protection: Complies with IP 66 | TYPE 4X, 12 | IK 10, when a bottom plate is fitted.

Material: Aluminium AlMg3. Frame: 2 mm. Door: 2 mm. Rear panel: 2 mm. Rain hood: 2 mm.

Lock: Espagnolette 4-point locking system. Does not interfere with the enclosure inner space. Standard lift handle with security lock.

Finish: RAL 7035 structure powder coating 100% polyester.

Door: Double walled with top and bottom ventilation openings, allowing air flow. Mounted with concealed hinges, allowing left or right hand opening. Multiple door version has individual lockable doors.

Delivery: Frame with fitted door with swinghandle, rear panel, rain hood. Delivery also includes earthing bolts.

Delivered on a pallet which is identical to the width of the enclosure to allow baying without removal. All packing material is recyclable. Mounting plate and bottom plates are not included in the standard delivery.

技术参数

厚度 (T): 2mm

材料: 铝

颜色: 浅灰色

完成: 粉末涂层

颜色代码: RAL 7035

Table 1/1						
物料号	高度 (H)	宽度 (W)	深度 (D)	门数量	重量	快速发货
EKOM12064-SW	1200mm	600mm	400mm	1	73kg	No
EKOM12066-SW	1200mm	600mm	600mm	1	45kg	No
EKOM12084-SW	1200mm	800mm	400mm	1	42kg	No
EKOM12086-SW	1200mm	800mm	600mm	1	52kg	No
EKOM12124-SW	1200mm	1200mm	400mm	2	65kg	No
EKOM14184-SW	1400mm	1800mm	400mm	3	134kg	No

图



警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE