


Console System Stainless Steel, MPCS

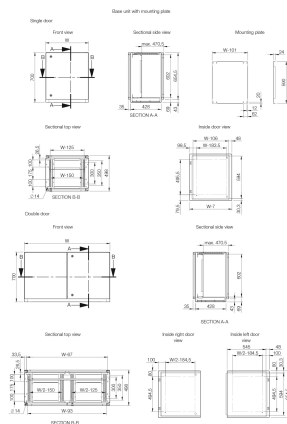

This stainless steel combinable console system, MPCS, has a IP 55/56 protection degree. It includes three interchangeable sections, top, desk and bottom. The system is very flexible and the various possible combinations can meet many design requirements. The ergonomic design of the top and desk units allows for easy installation and access to HMI-equipment, plus increases the mounting space available. This console can be installed in virtually any environment, grade dependent.

工业标准

UL 508A Listed; Type 12, 13, 4X; File No. E92044

cUL Listed per CSA C22.2 No. 14-13; Type 12, 13, 4X; File No. E92044

IEC 60529

CE, UK CA, UL, EAC

功能

Material: AISI 304 pre-grained stainless steel / AISI 316L (on request). Body and door: 2 mm. Rear panel: 1.5 mm. Bottom plates: 1.5 mm. Mounting plate: 2.5 mm galvanized steel.

Body: Folded and seam welded. Console construction includes a base that provides a distance between the floor and the lower part of the door/s, acting as an integrated plinth.

Doors and panels: Single folded surface mounted with hinges, allowing left and right-hand opening to base door. Top section and desk panels held open by self engage/self release mechanical panel stays. Concealed hinges allowing 90° opening on the desk. Double doors on 1200 mm and 1600 mm wide base units.

Mounting plate: Standard in base unit. Fixed by fixing brackets on C rail, top and bottom for depth adjustment. Optional in desk and top section units.

Lock: Double-bit 3 mm locks for top section and desk unit. For base, two double-bit 3 mm locks. Other options available. See wall mounting section.

Cable access: Bottom opening in base unit for cable access. Bottom plates for cable glanding supplied as standard.

Earthing: M8 threaded studs on bodies, doors and rear panels.

Finish: 400 pre-grained stainless steel.

Protection: Single door: IP 66, TYPE 4X, 12, 13, IK 10. Double door: IP 55, TYPE 12, 13, IK 10.

Delivery: The base unit is provided with a mounting plate as standard. Desk and top section units have mounting plates provided as accessories. All top and base apertures can be closed by choosing the appropriate accessory plate. Suitable nuts and washers for the various earthing studs are provided.

技术参数

厚度： 2mm
完成： 拉丝

Table 1/1						
物料号	高度	宽度	深度	材料	包含安装板	最大安装深度
MPCS061	500mm	600mm	494mm	不锈钢 304	否	
MPCS061-316	500mm	600mm	494mm	不锈钢 316L	否	
MPCS062-316	250mm	600mm	985mm	不锈钢 316L	否	
MPCS063	700mm	600mm	500mm	不锈钢 304	是	470.5mm
MPCS063-316	700mm	600mm	500mm	不锈钢 316L	是	470.5mm
MPCS081	500mm	800mm	494mm	不锈钢 304	否	
MPCS081-316	500mm	800mm	494mm	不锈钢 316L	否	
MPCS082	250mm	800mm	985mm	不锈钢 304	否	
MPCS082-316	250mm	800mm	985mm	不锈钢 316L	否	
MPCS083	700mm	800mm	500mm	不锈钢 304	是	470.5mm
MPCS083-316	700mm	800mm	500mm	不锈钢 316L	是	470.5mm
MPCS101	500mm	1000mm	494mm	不锈钢 304	否	
MPCS101-316	500mm	1000mm	494mm	不锈钢 316L	否	
MPCS102	250mm	1000mm	985mm	不锈钢 304	否	
MPCS102-316	250mm	1000mm	985mm	不锈钢 316L	否	

物料号	高度	宽度	深度	材料	包含安装板	最大安装深度
MPCS103	700mm	1000mm	500mm	不锈钢 304	是	470.5mm
MPCS103-316	700mm	1000mm	500mm	不锈钢 316L	是	470.5mm
MPCS121	500mm	1200mm	494mm	不锈钢 304	否	
MPCS121-316	500mm	1200mm	494mm	不锈钢 316L	否	
MPCS122	250mm	1200mm	985mm	不锈钢 304	否	
MPCS122-316	250mm	1200mm	985mm	不锈钢 316L	否	
MPCS123	700mm	1200mm	500mm	不锈钢 304	是	470.5mm
MPCS123-316	700mm	1200mm	500mm	不锈钢 316L	是	470.5mm
MPCS161	500mm	1600mm	494mm	不锈钢 304	否	
MPCS161-316	500mm	1600mm	494mm	不锈钢 316L	否	
MPCS162	250mm	1600mm	985mm	不锈钢 304	否	
MPCS162-316	250mm	1600mm	985mm	不锈钢 316L	否	
MPCS163	700mm	1600mm	500mm	不锈钢 304	是	470.5mm
MPCS163-316	700mm	1600mm	500mm	不锈钢 316L	是	470.5mm
MPCS062	250mm	600mm	985mm	不锈钢 304	否	

其他产品详情

Note: Only 1200 mm and 1600 mm wide consoles have double door. * On request.

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE