


Terminal box, 120x220x90, no MP, polyester, IP66

物料号

MGRP122209GE

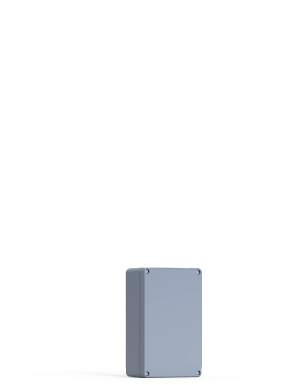

The polyester terminal box range, MGRP, a IP 66, 67 protection degree, is available off the shelf in many different sizes. The MGRP range is well suited for indoor and outdoor environments thanks to its high corrosion resistance while being UV resistant. Water and dust are prevented from entering the terminal box, thus eliminating the risk for component failure, and with that, unnecessary downtime.

工业标准

cULus_UL Listed

GOST

CE UKCA

功能

Description: Polyester box. Suitable for outdoor use, UV-resistant according to UL746 C.

Material: Glass fibre reinforced polyester.

Gasket: Standard supply fitted with a polyurethane gasket. Silicone, neoprene and EPDM gaskets are available on request.

Temperature resistance: -40 °C to +100 °C with the standard polyurethane gasket; -60 °C to +130 °C with the silicone gasket; -35 °C to +100 °C with the EPDM gasket; -30 °C to +80 °C with the neoprene gasket.

Flammability: UL94 V-0.

Protection: IP 66, 67 | IK 08, 07 for MGRP08080xGE.

Finish: RAL 7000.

Approvals: CE, GOST. For cULus_UL Listed approvals, please contact our sales department.

Delivery: Body, cover and cover screws. Cover screws made of stainless steel.

Note: Mounting plate, GMP, and hinges, HHI, are available separately.

产品属性

高度: 120mm

宽度: 220mm

深度: 90mm

主体厚度: 4.5mm

盖板厚度: 4mm

盖板螺钉数量: 4

重量: 1.1kg

材料: 聚酯

完成: 平滑

颜色: 松鼠灰

颜色代码: RAL 7000

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE