


TFP4 Side-Mount Filter Fan Type 1, 24V 55CFM, Light Gray, Composite

物料号

TFP424

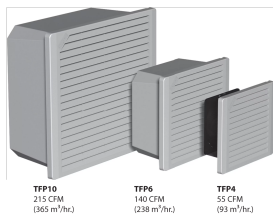

TFP Side-Mount Fans provide reliable cooling for enclosures with limited space requiring simple filtered airflow for basic cooling. Engineered for 50,000 hours of continuous operation without lubrication or service.

工业标准

TFP# UL 12 型号: Type 12

TFP# Models: Type 1

TFP# UL 12 Models: Type 12

CSA 认证 (仅限风扇)

CE

功能

冷却风扇套件包含风扇、空气过滤器、复合气室、护手板和格栅

排气套件包括空气过滤棉、带护手板和格栅的过滤棉固定器

EMC 升级套件包含一个格栅隔离圈和一个特制的 EMC 屏蔽格栅

为空间有限且需要气流进行冷却的机柜提供可靠的冷却解决方案。

聚碳酸酯动态平衡风扇叶轮

配备所有安装硬件和安装说明

24 VDC, 115 VAC and 230 VAC options available

Washable foam (Type 1) or disposable (Type 12) filter in fan

4-inch fan is thermally protected and uses permanently-lubricated ball bearings

6- and 10-inch fans have ball bearing construction and split-capacitor motors that are thermally protected to avoid premature failure

Fans have lead wires for power connection with ends stripped 1/2 in. (12 mm)

Free airflow from 45 CFM (76 mm cu/hr.) to 215 CFM (365 mm cu/hr.)

Maximum operating temperature 158 F / 70 C

Engineered for 50,000 hours of continuous operation without lubrication or service (a monthly maintenance schedule is recommended to ensure optimal cooling performance)

产品属性

订货号: 17387

气流: 93m³/h

标称电压: 24V

高度: 160mm

宽度: 187mm

深度: 76mm

最大电流: 0.35A

工作温度: 70°C max

材料: 复合

完成: 平滑哑光

颜色: 浅灰色

颜色代码: RAL 7035

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE