


Large Abs Terminal Box, OABP

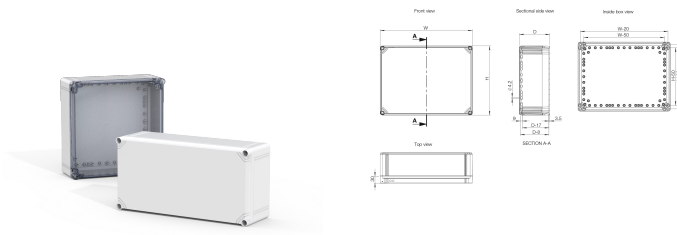

This ABS terminal box range, OABP, with a IP 66, 67 protection degree, can be extended in depth. It is available off the shelf in many different sizes. Deeper components may be installed when an extension frame, OPCP-EE, is used. The OABP range is well suited for demanding environments, since water and dust are prevented from entering the terminal box, thus eliminating the risk for component failure, and with that unnecessary downtime.

工业标准

CE UKCA

GOST

IP

功能

Description: ABS box, halogen-free, suitable for indoor use. Low UV radiation resistance.

Material: Body: ABS. Plain cover: ABS. Transparent cover: polycarbonate.

Gasket: Polyurethane gasket integrated in the box cover.

Temperature resistance: -40 °C to +60 °C.

Flammability: UL94 HB.

Protection: IP 66, 67 | IK 06 (-25 °C), IK 07 (+35 °C).

Finish: RAL 7035.

Delivery: Body, cover, cover screws manufactured from polyamide and mounting screws.

The installed components inside the terminal box will be safe and secure due to the high protection degree

Customers can receive terminal boxes with a short delivery time, that match their size requirements

This will also remove any extra costs due to oversizing

Component failure and unnecessary downtime is avoided as water and dust are prevented from entering the terminal box

If necessary, deeper components can be installed when the expansion frame, OPCP-EE, has been mounted.

The mounting plate, OMP, and DIN profiles, DR, have to be ordered separately, in order to complete the installation of the terminal box

The expansion frame, OPCP-EE, should be ordered if a deeper terminal box is required

Inner depth (mm): 115

技术参数

材料: ABS
颜色: 浅灰色
颜色代码: RAL 7035
完成: 平滑

Table 1/1						
物料号	高度	宽度	深度	盖板样式	最大安装深度	重量
OABP202013GE	200mm	200mm	132mm	灰色	115mm	1.1kg
OABP202013TE	200mm	200mm	132mm	清除	115mm	1.1kg
OABP203013GE	200mm	300mm	132mm	灰色	115mm	1.5kg
OABP203013TE	200mm	300mm	132mm	清除	115mm	1.5kg
OABP204013GE	200mm	400mm	132mm	灰色	115mm	1.8kg
OABP204013TE	200mm	400mm	132mm	清除	115mm	1.9kg
OABP303013GE	300mm	300mm	132mm	灰色	115mm	1.9kg
OABP303013TE	300mm	300mm	132mm	清除	115mm	1.9kg
OABP304013GE	300mm	400mm	132mm	灰色	115mm	2.3kg
OABP304013TE	300mm	400mm	132mm	清除	115mm	2.4kg
OABP306013GE	300mm	600mm	132mm	灰色	115mm	3.2kg
OABP306013TE	300mm	600mm	132mm	清除	115mm	3.4kg
OABP406013GE	400mm	600mm	132mm	灰色	115mm	4kg
OABP406013TE	400mm	600mm	132mm	清除	115mm	4.1kg

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE