


Large Polycarbonate Terminal Box, OPCP

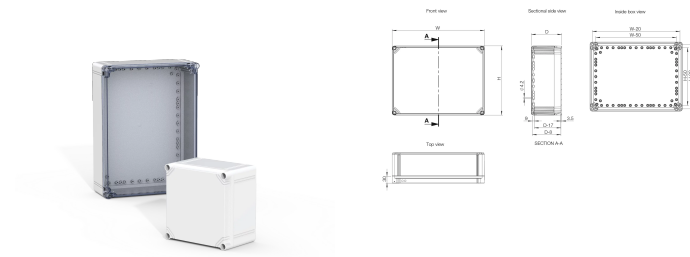

This polycarbonate terminal box range, OPCP, with a IP 66, 67 protection degree, can be extended in depth. It is available off the shelf in many different sizes. Deeper components may be installed when an extension frame, OPCP-EE, is used. The OPCP range is well suited for indoor and outdoor environments, even in locations where there is direct sunlight, thanks to the resistance to UV radiation. Water and dust are prevented from entering the terminal box, thus eliminating the risk for component failure, and with that, unnecessary downtime.

工业标准

CE UKCA

GOST

IP

功能

Description: Polycarbonate box, halogen-free, suitable for outdoor use. High UV radiation resistance. Self-extinguishing.

Material: Polycarbonate.

Gasket: Polyurethane gasket integrated in the box cover.

Temperature resistance: -40 °C to +80 °C.

Flammability: UL746C 5V.

Protection: IP 66, 67 | IK 08 (-25 °C ... +35 °C).

Finish: RAL 7035.

Approvals: CE, GOST. For cULus_UL Listed, please contact our sales department.

Delivery: Body, cover, cover screws manufactured from polyamide and mounting screws.

Customers can receive terminal boxes with a short delivery time, that match their size requirements which can be installed in both indoor and outdoor environments, even in locations where there is direct sunlight

This will also remove any extra costs due to oversizing

Component failure and unnecessary downtime is avoided as water and dust are prevented from entering the terminal box

If necessary, deeper components can be installed when the expansion frame, OPCP-EE, has been mounted

The mounting plate, OMP, and DIN profiles, DR, have to be ordered separately, in order to complete the installation of the terminal box

The expansion frame, OPCP-EE, should be ordered if a deeper terminal box is required

Inner depth (mm): 115

技术参数


颜色：浅灰色

材料：聚碳酸酯

颜色代码：RAL 7035

完成：平滑

Table 1/1						
物料号	高度 (H)	宽度 (W)	深度 (D)	盖板样式	最大安装深度	重量
OPCP202013GE	200mm	200mm	132mm	灰色	115mm	1.3kg
OPCP202013TE	200mm	200mm	132mm	清除	115mm	1.3kg
OPCP203013GE	200mm	300mm	132mm	灰色	115mm	1.7kg
OPCP203013TE	200mm	300mm	132mm	清除	115mm	1.7kg
OPCP204013GE	200mm	400mm	132mm	灰色	115mm	2kg
OPCP204013TE	200mm	400mm	132mm	清除	115mm	2kg
OPCP304013TE	300mm	400mm	132mm	清除	115mm	2kg
OPCP303013TE	300mm	300mm	132mm	清除	115mm	2.1kg
OPCP303013GE	300mm	300mm	132mm	灰色	115mm	2.2kg
OPCP304013GE	300mm	400mm	132mm	灰色	115mm	2.7kg
OPCP306013TE	300mm	600mm	132mm	清除	115mm	3.5kg
OPCP306013GE	300mm	600mm	132mm	灰色	115mm	3.6kg
OPCP406013GE	400mm	600mm	132mm	灰色	115mm	4.5kg
OPCP406013TE	400mm	600mm	132mm	清除	115mm	4.5kg

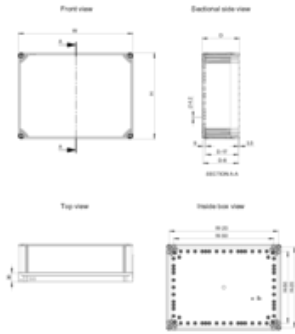

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE