

模块化双开门，MCDS

The stainless steel double door combinable floor standing enclosure range, MCDS, is ideal for installation in confined spaces where a single door, when opened, would take up too much space in front of the enclosure. The doors' loading capacity also increases as it is divided over two doors. With a IP 55 protection degree, components inside the enclosure are well protected and makes it well suited for almost any environment, grade dependent.



工业标准

cUL 认证 (根据 CSA C22.2 No.0、No.0.4、No.14、No.94; Type 12; 文件编号 E92044

cUL Listed per CSA C22.2 No.0, No.0.4, No.14, No.94; Type 12; File No. E92044

NEMA/EEMAC Type 12

IEC 62208 IP55

CE, UK CA, UL, DNV, EAC

功能

Levering inkluderer: Ramme med monterede døre, bagpanel, toppanel, bundplader, monteringsplade og dørramme. Levering omfatter også bolte til jording. Leveres på palle i samme bredde som skabet, så skabene kan kombineres uden at fjerne dem fra pallerne. Alt emballeringsmateriale kan genbruges.}

Material: AISI 304L pre-grained stainless steel / AISI 316L. Frame: 1.5 mm. Door: 2 mm. Rear, roof and side panels: 1.5 mm. Bottom plates: 1.5 mm stainless steel. Mounting plate: 3 mm galvanized steel.

Frame: Seam welded reversed open profiles with 25 mm hole pattern, according to DIN 43660.

Door: Mounted with four hinges. Including door frame with 25 mm hole pattern. Doors cannot be reversed. Separate doors to be ordered for left hand door locking.

Rear panel: Fitted by M6 torx screws. Standard facilities for rear door mounting. Split rear panels in 1600 mm wide enclosures.

Side panels: Supplied as an accessory.

Roof panel: Removable.

Lock: Espagnolette 4-point locking system in the main door and 2-point locking system in the slave door. Standard double-bit lock with 3 mm insert. Standard inserts, cylinders, lift handles and T-handle are available as accessories.

Bottom plates: Two piece bottom plate in 1200 mm width, with injected polyurethane gasket to ensure maximum sealing.

Mounting plate: Double folded and adjustable in depth by steps of 25 mm, with the MPD02 accessory. Mounting plate is delivered, attached on the outside of the enclosure packaging.

Earthing: All panels are earthed through their fittings and are equipped with a separate earthing stud.

Finish: 400 pre-grained stainless steel.

Protection: Complies with IP 55 | TYPE 12 | IK 10.


Mounting requirements: Standard delivery ready for combined installation. For stand-alone installation, add side panels.

技术参数

主体厚度: 1.5mm
门厚: 2mm
完成: 拉丝

Table 1/1						
物料号	订货号	高度 (H)	宽度 (W)	深度 (D)	材料	快速发货
MCDS18105		1800mm	1000mm	500mm	不锈钢 304	No
MCDS18105-316		1800mm	1000mm	500mm	不锈钢 316	No
MCDS18125		1800mm	1200mm	500mm	不锈钢 304	No
MCDS18125-316		1800mm	1200mm	500mm	不锈钢 316	No
MCDS20126	MCDS20126	2000mm	1200mm	600mm	不锈钢	No
MCDS20126-316		2000mm	1200mm	600mm	不锈钢 316	No

图

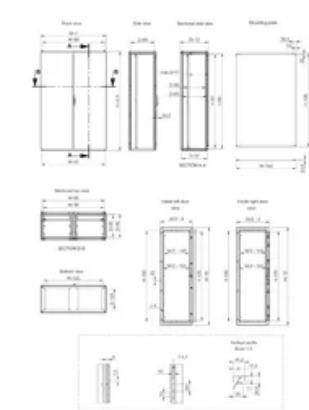

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE