

模块化单开门，MCSS-HP



The stainless steel single door combinable floor standing enclosure range, MCSS-HP, with a IP 66 protection degree offers a higher protection level for equipment and components which will help extend their lifetime and reduce maintenance costs when the enclosure is installed for rough environments with severe conditions. These new enclosures are rated as IP66 even if they are bayed between them using the standard baying brackets.

工业标准

CE, UK CA, UL

NEMA 4X、12、13 型

IP66

IK10

功能

Dør: Monteret med fire hængsler til venstre- eller højreåbning. Inklusive dørramme med 25 mm hulmønster.}

Delivery: Frame with fitted door, rear panel, roof panel, bottom plate, mounting plate and door frame. Delivery also includes earthing bolts. Delivered on a pallet which is identical to the width of the enclosure to allow baying without removal. All packing material is recyclable.

Mounting requirements: For stand-alone installation, add side panels. For combined installation, HPPG01 and baying brackets, CCI and CCM are required.

Earthing: All panels are earthed through their fittings and are equipped with a separate earthing stud.

Bottom plates: One piece bottom plate, with injected polyurethane gasket to ensure maximum sealing.

Side panels: Supplied as an accessory.

Roof panel: Removable.

Rear panel: Fitted by M6 torx screws. Standard facilities for rear door mounting.

Protection: Complies with IP 66, TYPE 4X, 12, IK 10.

Mounting plate: Double folded and slides into position. Adjustable in depth by steps of 25 mm, with the MPD02 accessory. Mounting plate is supplied, attached on the outside of the enclosure packaging.

Material: AISI 304L pre-grained stainless steel / AISI 316L (on request). Frame: 1.5 mm. Door: 2 mm. Rear, roof and side panels: 1.5 mm. Bottom plates: 1.5 mm stainless steel. Mounting plate: 3 mm galvanized steel.

Lock: Espagnolette 4-point locking system. Does not interfere with the enclosure inner space. Standard double-bit lock with 3 mm insert. Standard inserts, cylinders, lift handles and T-handles are available as accessories.

Frame: Seam welded reversed open profiles with 25 mm hole pattern, according to DIN 43660. Including integrated external hole pattern.

Finish: 400s pre-grained stainless steel (0.5 microns average).

技术参数


- 主体厚度: 1.5mm
- 门厚: 2mm
- 完成: 拉丝
- 材料: 不锈钢

Table 1/1						
物料号	订货号	高度 (H)	宽度 (W)	深度 (D)	最大安装深度	快速发货
MCSS20086HP	MCSS20086HP	2000mm	800mm	600mm	559mm	No
MCSS22088HP		2200mm	800mm	800mm	759mm	No

其他产品详情

*Other dimensions available on request. Special side panel is required if depth is greater than 700 mm.

图

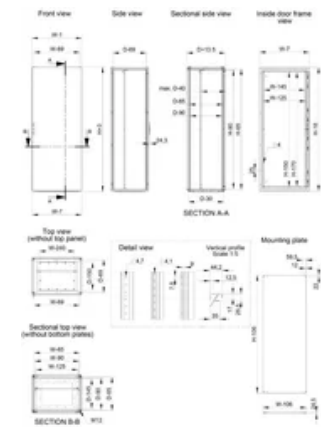

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE