

模块化单开门机柜，高防护，MCS-HP



The mild steel single door combinable floor standing enclosure range, MCS-HP, with a IP 66 protection degree offers a higher protection level for equipment and components which will help extend their lifetime and reduce maintenance costs when the enclosure is installed for rough environments with severe conditions. These new enclosures are rated as IP66 even if they are bayed using the standard baying brackets.

工业标准

CE, UK CA, UL

NEMA 4、12 型

IP66

IK10

功能

Levering inkluderer: Ramme med monteret dør, bagpanel, toppanel, bundplade, monteringsplade og dørramme.
Levering omfatter også jordingsbolte. Leveres på en palle med samme bredde som skabet, hvilket muliggør tilpasning uden afmontering fra pallen. Alle emballeringsmaterialer er genanvendelige.}

Material: Frame: 1.5 mm painted steel. Door: 2 mm painted steel. Rear, roof and side panels: 1.5 mm painted steel. Mounting plate: 3 mm galvanized steel. Bottom plates: 1 mm galvanized steel.

Frame: Seam welded reversed open profiles with 25 mm hole pattern according to DIN 43660. Including integrated external hole pattern.

Door: Mounted with four hinges allowing left or right hand opening. Including door frame with 25 mm hole pattern.

Rear panel: Fitted by M6 torx screws. Standard facilities for rear door mounting.

Side panels: Supplied as an accessory.

Roof panel: Removable.

Lock: Espagnolette 4-point locking system. Does not interfere with the enclosure inner space. Standard double-bit lock with 3 mm insert. Standard inserts, cylinders, lift handles and T-handles are available as accessories.

Bottom plates: One piece bottom plate, with injected polyurethane gasket to ensure maximum sealing.

Mounting plate: Double folded and slides into position. Adjustable in depth by steps of 25 mm, with the MPD02 accessory. Supplied, attached on the outside of the enclosure packaging.

Earthing: All panels are earthed through their fittings and are equipped with a separate earthing stud.

Finish: RAL 7035 structured powder coating.

Protection: Complies with IP 66 | TYPE 4, 12 | IK 10.


Mounting requirements: Standard delivery ready for combined installation. For stand-alone installation add side panels.

技术参数

主体厚度: 1.5mm
门厚: 2mm
颜色: 浅灰色
材料: 低碳钢
完成: 粉末涂层
颜色代码: RAL 7035

Table 1/1						
物料号	订货号	高度 (H)	宽度 (W)	深度 (D)	最大安装深度	快速发货
MCS22088HP		2200mm	800mm	800mm	759mm	No
MCS20086HP	MCS20086HP	2000mm	800mm	600mm	559mm	No

图

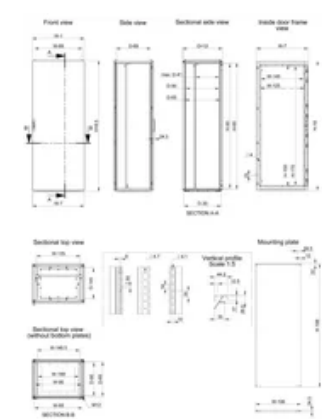

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE