


Mounting Plates For Power Distribution, MSMPN

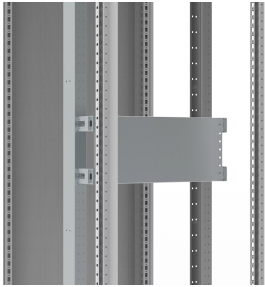

The mounting plate, MSMPN, for fix and modular systems, can be easily machined and have components mounted on it before fixed within the relevant compartment.

功能

Description: Mounting plate for installation of breakers. Suitable for left and right hand connections.

Material: 1.5 mm galvanized steel.

Pack quantity: 1 piece with mounting material.

Mounting requirements: To be assembled on the modular system frame with MSMPA01 or MSMPF01.

技术参数

完成： 电镀
材料： 钢

Table 1/1						
物料号	高度	宽度	类型	适配外壳尺寸	面板尺寸	外壳材料
MSMPN1008H	10mm	800mm	水平开口	100 x 800mm	96 x 670mm	低碳钢
MSMPN0506	50mm	600mm	普通	50 x 600mm	496 x 470mm	低碳钢
MSMPN0508	50mm	800mm	普通	50 x 800mm	496 x 670mm	低碳钢
MSMPN1006	100mm	600mm	普通	100 x 600mm	96 x 470mm	低碳钢
MSMPN1006H	100mm	600mm	水平开口	100 x 600mm	96 x 470mm	低碳钢
MSMPN1008	100mm	800mm	普通	100 x 800mm	96 x 670mm	低碳钢
MSMPN1506	150mm	600mm	普通	150 x 600mm	146 x 470mm	低碳钢
MSMPN1506V	150mm	600mm	垂直开口	150 x 600mm	146 x 470mm	低碳钢
MSMPN1508	150mm	800mm	普通	150 x 800mm	146 x 670mm	低碳钢
MSMPN1508V	150mm	800mm	垂直开口	150 x 800mm	146 x 670mm	低碳钢
MSMPN2006	200mm	600mm	普通	200 x 600mm	196 x 470mm	低碳钢
MSMPN2006V	200mm	800mm	垂直开口	200 x 600mm	196 x 470mm	低碳钢
MSMPN2008	250mm	600mm	普通	200 x 800mm	196 x 670mm	低碳钢
MSMPN2008V	200mm	800mm	垂直开口	200 x 800mm	196 x 670mm	低碳钢
MSMPN2506	250mm	600mm	普通	250 x 600mm	246 x 470mm	低碳钢

物料号	高度	宽度	类型	适配外壳尺寸	面板尺寸	外壳材料
MSMPN2506V	250mm	600mm	垂直开口	250 x 600mm	246 x 470mm	低碳钢
MSMPN2508	250mm	800mm	普通	250 x 800mm	246 x 670mm	低碳钢
MSMPN2508V	250mm	800mm	垂直开口	250 x 800mm	246 x 670mm	低碳钢
MSMPN3006	300mm	600mm	普通	300 x 600mm	296 x 470mm	低碳钢
MSMPN3006V	300mm	600mm	垂直开口	300 x 600mm	296 x 470mm	低碳钢
MSMPN3008	300mm	800mm	普通	300 x 800mm	296 x 670mm	低碳钢
MSMPN3008V	300mm	800mm	垂直开口	300 x 800mm	296 x 670mm	低碳钢
MSMPN4006	400mm	600mm	普通	400 x 600mm	396 x 470mm	低碳钢
MSMPN4006V	400mm	600mm	垂直开口	400 x 600mm	396 x 470mm	低碳钢
MSMPN4008	400mm	800mm	普通	400 x 800mm	396 x 670mm	低碳钢
MSMPN4008V	400mm	800mm	垂直开口	400 x 800mm	396 x 670mm	低碳钢
MSMPN4506	450mm	600mm	普通	450 x 600mm	446 x 470mm	低碳钢
MSMPN4506V	450mm	600mm	垂直开口	450 x 600mm	446 x 470mm	低碳钢
MSMPN4508	450mm	800mm	普通	450 x 800mm	446 x 670mm	低碳钢
MSMPN4508V	450mm	800mm	垂直开口	450 x 800mm	446 x 670mm	低碳钢
MSMPN5006	500mm	600mm	普通	500 x 600mm	496 x 470mm	低碳钢
MSMPN5008	500mm	800mm	普通	500 x 800mm	496 x 670mm	低碳钢
MSMPN6006	600mm	600mm	普通	600 x 600mm	596 x 470mm	低碳钢

物料号	高度	宽度	类型	适配外壳尺寸	面板尺寸	外壳材料
MSMPN6006V	600mm	600mm	垂直开口	600 x 600mm	596 x 470mm	低碳钢
MSMPN6008	600mm	800mm	普通	600 x 800mm	596 x 670mm	低碳钢
MSMPN6008V	600mm	1000mm	垂直开口	600 x 800mm	596 x 670mm	低碳钢
MSMPN6010	600mm	1000mm	普通	600 x 1000mm	596 x 870mm	低碳钢

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE