


安装型材 19 英寸半高，CIPP

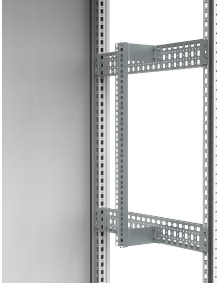

These partial profiles, that can be adjustable in height and depth , allow for the installation of 19" equipment, while customers maintain access to the components installed on the mounting plate within the enclosure.

功能

Description: Partial height 19" vertical profiles to achieve 482.6 mm (19") mounting requirements on all sides.
Adjustable in depth in steps of 25 mm using the CLPK click-in profiles.

Material: 2 mm zinc plated steel.

Pack quantity: 2 pieces with mounting accessories.

Mounting requirements: To be used with brackets CIC in 800 mm wide enclosures.

技术参数

厚度: 2mm
材料: 低碳钢
完成: 镀锌

Table 1/1						
物料号	订货号	高度	宽度	深度	机架单元	外壳材料
CIPP06	CIPP06	267mm	45mm	29mm	6U	低碳钢
CIPP09	CIPP09	400mm	45mm	29mm	9U	低碳钢
CIPP10	CIPP10	445mm	45mm	29mm	10U	低碳钢
CIPP11	CIPP11	489mm	45mm	29mm	11U	低碳钢
CIPP13	CIPP13	578mm	45mm	29mm	13U	低碳钢
CIPP15	CIPP15	667mm	45mm	29mm	15U	低碳钢
CIPP18	CIPP18	800mm	45mm	29mm	18U	低碳钢

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE