


One-Piece Consoles In Stainless Steel, MPGS

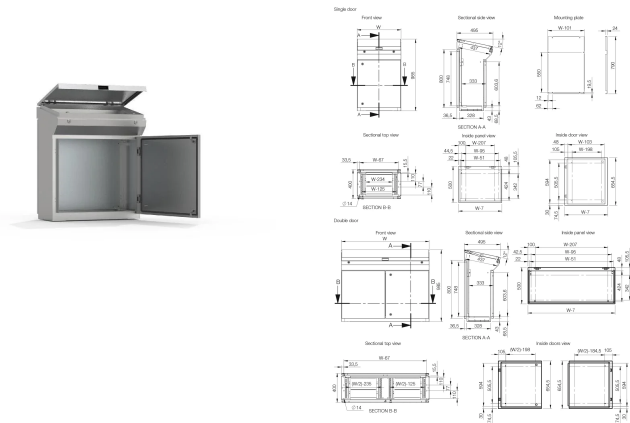

The stainless steel compact console, MPGS, in a IP66/55 protection degree is available off the shelf. It has a hinged desk panel, and the ergonomic design allows for easy installation and access to HMI-equipment- It also increases the mounting space available. This console can be installed in virtually any environment, grade dependent.

工业标准

cULus_UL Listed

CE, UK CA, UL, EAC

功能

Material: AISI 304 pre-grained stainless steel / AISI 316L (on request). Body and door: 2 mm. Rear panel: 1.5 mm. Bottom plates: 1.5 mm. Mounting plate: 2.5 mm galvanized steel.

Body: Folded and seam welded. Console construction includes a base that provides a distance between the floor and the lower part of the door/s, acting as an integrated plinth.

Doors and panels: Single folded surface mounted with hinges, allowing left and right-hand opening to base door. Angle 12° from horizontal. Concealed hinges, on top edge, allow 90° opening. Panel held open by self engage/self release mechanical panel stay. Double door on 1200 wide base units.

Mounting plate: Standard mounting plate in base unit.

Lock: Double-bit 3 mm locks for top panel. For base, two double-bit 3 mm locks.

Cable inlet: Bottom opening for cable access. Bottom plate for cable glanding supplied as standard.

Earthing: M8 threaded studs on body, door, top panel and rear panel.

Finish: 400 pre-grained stainless steel.

Protection: Single door: IP 66, TYPE 4X, 12, 13, IK 10. Double door: IP 55, TYPE 12, 13, IK 10.

Delivery: Mounting plate and suitable nuts and washers for earthing. The console is delivered on a wooden pallet.

技术参数

主体厚度: 2mm
门厚: 2mm
完成: 拉丝

Table 1/1						
物料号	高度	宽度	深度	面板尺寸	最大安装深度	重量
MPGS06	985mm	600mm	400mm	790 x 499mm	357.5mm	60kg
MPGS06-316	985mm	600mm	400mm	790 x 499mm	357.5mm	60kg
MPGS08	985mm	800mm	400mm	790 x 699mm	357.5mm	73.72kg
MPGS08-316	985mm	800mm	400mm	790 x 699mm	357.5mm	73.72kg
MPGS10	985mm	1000mm	400mm	790 x 899mm	357.5mm	80kg
MPGS10-316	985mm	1000mm	400mm	790 x 899mm	357.5mm	80kg
MPGS12	985mm	1200mm	400mm	790 x 1099mm	357.5mm	90.67kg
MPGS12-316	985mm	1200mm	400mm	790 x 1099mm	357.5mm	90.67kg

其他产品详情

Note: Only 1200 mm wide consoles have double door. * On request.

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE