


Operator Interface Control Panel, OICP

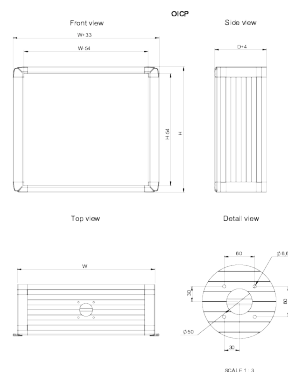

The aluminium operator interface control panel, OICP, has a pre-machined hole pattern to allow for the desired fixation to a swing arm, plus a removable front plate at a IP 65 protection degree. Components can be easily fitted thanks to the removable front plate, but will also be easily accessible through a removable rear panel. Side handles on the enclosure allow for easy movement of the enclosure into the desired working position. The aluminium body will dissipate more heat than a mild steel body, which may eliminate the need for additional ventilation.

工业标准

CE UKCA

EAC

GOST

功能

Material: Body: Al Mg Si05. Rear plate: Al Mg. Corners: AlSi 12.

Protection: IP 65.

Finish: Body and rear plate: anodised aluminium. Corners: RAL 7016.

Mounting requirements: OIFP front panel is not included in the standard delivery and needs to be ordered separately.

Delivery: Body, screwed rear plate, front plate mounting kit, and mounting accessories.

技术参数

材料:	铝
颜色:	煤灰色
完成:	粉末涂层
颜色代码:	RAL 7016

Table 1/1					
物料号	高度	宽度	深度	重量	快速发货
OICP343920	345mm	395mm	200mm	7kg	No
OICP305220	309mm	525mm	200mm	7.9kg	No
OICP355220	345mm	525mm	200mm	8.3kg	No
OICP395220	398mm	525mm	200mm	9kg	No
OICP414720	415mm	470mm	200mm	8.5kg	No
OICP495420	495mm	542mm	200mm	10.3kg	No

其他产品详情

The external enclosure dimension is increased by 16.5 mm, on the side where there is a grip profile.

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE