


外部安装型材，CLPO

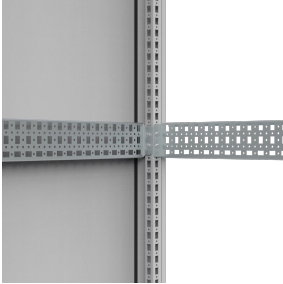

A standard, off the shelf accessory compatible with nVent HOFFMAN's standard hole pattern, which simplifies procurement and installation.

功能

Description: Universal profile for both depth and width fitting on the 25 mm DIN hole pattern on the enclosure frame. The 75 mm wide profile is equipped with three rows of holes of which one is turned 90°. This makes it possible to mount the CLPO profiles in both directions. The CLPO increases the useful space by 25 mm.

Material: 1.5 mm zinc plated steel.

Pack quantity: 4 profiles.

技术参数

厚度: 1.5mm
完成: 镀锌
材料: 低碳钢

Table 1/1						
物料号	订货号	高度	宽度	深度	额定负载	外壳材料
CLPO1000	CLPO1000	74mm	43mm	911mm	1400N	低碳钢
CLPO1200	CLPO1200	74mm	43mm	1111mm	1200N	低碳钢
CLPO400	CLPO400	74mm	43mm	311mm	2400N	低碳钢
CLPO500	CLPO500	74mm	43mm	411mm	2400N	低碳钢
CLPO600	CLPO600	74mm	43mm	511mm	2400N	低碳钢
CLPO800	CLPO800	74mm	43mm	711mm	1800N	低碳钢
CLPO300		74mm	43mm	211mm	2400N	低碳钢

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE