


侧板，SPM

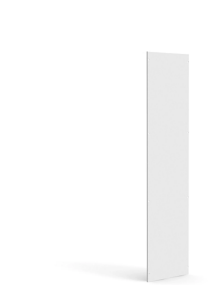

用以密封机柜两侧，保护电气组件在没有任何干扰的情况下运行，并防止人员受伤害。

功能

Description: Easy one man assembly. Sealed by an extruded, one piece polyurethane gasket and mounted with 8 screws and new patented retainers. Can be replaced by the side door DNS.

Material: 1.5 mm steel plate.

Finish: RAL 7035 structured powder coating.

Protection: IP 55, TYPE 12, 13 in combination with MCS. IP66, TYPE 4, 12, 13 in combination with MCS-HP.

Pack quantity: 2 panels with mounting accessories.

技术参数

厚度: 1.5mm
颜色: 浅灰色
材料: 低碳钢
完成: 粉末涂层
颜色代码: RAL 7035

Table 1/1						
物料号	订货号	高度	宽度	深度	外壳材料	快速发货
SPM1106R5		1100mm	19mm	600mm	低碳钢	No
SPM1606R5	SPM1606R5	1600mm	19mm	600mm	低碳钢	No
SPM1406R5	SPM1406R5	1400mm	19mm	600mm	低碳钢	No
SPM1808R5	SPM1808R5	1800mm	19mm	800mm	低碳钢	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE