


滑轨

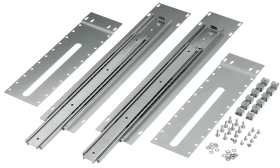

Heavy-duty ball bearing, plated three-section Slides are 16-in. (406-mm) long and allow 17-in. (423-mm) extension. They are attached to supports that mount between two pairs of rack mounting angles that have accessory mounting legs. Mounting hardware is furnished. Equipment 16.75-in. (425-mm) wide can be mounted between Slide assemblies installed on 19-in. rack angles. A pair of Slides can support up to 160 lbs. at the extended position when load is distributed evenly along the 16-in. (406-mm) Slide length. Requires Rack Angle Adapter Bracket to fit ProLine.

功能

滑块附接到两对机架安装角之间的支撑，这些安装角带附件安装支腿。

提供安装五金件

Heavy-duty ball bearing slides are 16-in. (406-mm) long and allow 17-in. (423-mm) extension

A pair of Slides can support up to 160 lbs. (72 kg) at the extended position when load is distributed evenly

技术参数

Table 1/1			
物料号	材料	完成	快速发货
IA16SL2U0000S	低碳钢	镀锌	No

其他产品详情

Needs to be used with the Rack Angle Adapter Bracket (PBRAA, PBRAA19 or PBRAA24).

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE