


Small ABS Terminal Box, DABP

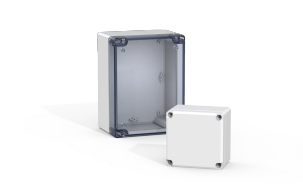

The ABS terminal box range, DABP, with a IP 66, 67 protection degree, is available off the shelf in many different sizes. The DABP range is well suited for demanding environments, since water and dust are prevented from entering the terminal box, thus eliminating the risk for component failure, and with that unnecessary downtime.

工业标准

CE
UKCA
GOST
IP

功能

Description: ABS box, halogen-free, suitable for indoor use. Low UV radiation resistance.

Material: Body: ABS. Plain cover: ABS. Transparent cover: polycarbonate.

Gasket: Polyurethane gasket integrated in the box cover.

Temperature resistance: -40 °C to +60 °C.

Flammability: UL94 HB.

Protection: IP 66, 67 | IK 06 (-25 °C), IK 07 (+35 °C).

Finish: RAL 7035.

Delivery: Body, cover, cover screws manufactured from stainless steel, mounting screws and cover plugs made from polyamide.

Low UV radiation resistance

Polyurethane gasket integrated in the box cover

Temperature resistance: -40 °C to +60 °C

Flammability: UL94 HB

Body, cover, cover screws manufactured from stainless steel, mounting screws and cover plugs made from polyamide

技术参数

材料： ABS
颜色： 浅灰色
完成： 平滑


Table 1/1						
物料号	高度 (H)	宽度 (W)	深度 (D)	最大安装深度	重量	快速发货
DABP080806GE	80mm	82mm	86mm	42mm	0.1kg	No
DABP080809GE	80mm	82mm	56mm	72mm	0.1kg	No
DABP081206GE	80mm	120mm	56mm	42mm	0.15kg	No
DABP081209GE	80mm	120mm	86mm	72mm	0.2kg	No
DABP081606GE	80mm	160mm	56mm	42mm	0.2kg	No
DABP081609GE	80mm	160mm	86mm	72mm	0.2kg	No
DABP121206GE	120mm	122mm	56mm	42mm	0.2kg	No
DABP121209GE	120mm	122mm	86mm	72mm	0.25kg	No
DABP121609GE	120mm	160mm	91mm	77mm	0.35kg	No
DABP122009GE	120mm	200mm	86mm	72mm	0.35kg	No
DABP152008GE	150mm	200mm	76mm	62mm	0.4kg	No
DABP050504GE	53mm	55mm	36mm	27.5mm	0.5kg	No
DABP162409GE	160mm	240mm	91mm	77mm	0.55kg	No
DABP162412GE	160mm	240mm	121mm	107mm	0.7kg	No
DABP050704GE	53mm	65mm	36mm	25mm	0.8kg	No

物料号	高度 (H)	宽度 (W)	深度 (D)	最大安装深度	重量	快速发货
DABP233009GE	230mm	300mm	86mm	72mm	0.85kg	No
DABP233011GE	230mm	300mm	111mm	97mm	1kg	No

其他产品详情

Note: Terminal box, with polycarbonate transparent cover fitted, can be ordered by replacing GE with TE in the item number.

图

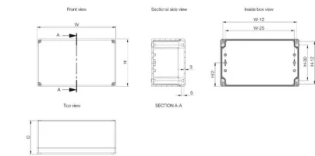

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE