


Split Bottom Plates Stainless Steel, CBPS

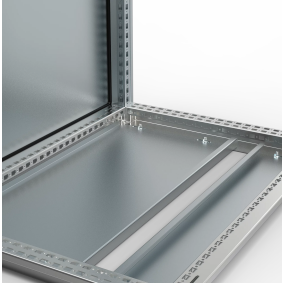

A split bottom plate offers a flexible cabling solution and eliminates the need for individual cable glands. The protection degree is maintained by using a separate gasket.

功能

Description: Fitted in place of the standard one piece bottom plate, allows direct cable entry. To achieve perfect sealing around the cables use the gasket kit BG01.

Material: AISI 304 / AISI 316L pre-grained stainless steel.

Bottom plates: 1.5 mm.

Finish: 400 pre-grained stainless steel.

Pack quantity: 1 kit of two part bottom plate.

技术参数

厚度： 1.5mm
完成： 拉丝

Table 1/1						
物料号	高度	宽度	深度	外壳材料	材料	快速发货
CBPS0640	25mm	600mm	400mm	不锈钢	不锈钢 304	No
CBPS0640-316	25mm	600mm	400mm	不锈钢	不锈钢 316	No
CBPS0650	25mm	600mm	500mm	不锈钢	不锈钢 304	No
CBPS0650-316	25mm	600mm	500mm	不锈钢	不锈钢 316	No
CBPS0660	25mm	600mm	600mm	不锈钢	不锈钢 304	No
CBPS0660-316	25mm	600mm	600mm	不锈钢	不锈钢 316	No
CBPS0840	25mm	800mm	400mm	不锈钢	不锈钢 304	No
CBPS0840-316	25mm	800mm	400mm	不锈钢	不锈钢 316	No
CBPS0850	25mm	800mm	500mm	不锈钢	不锈钢 304	No
CBPS0850-316	25mm	800mm	500mm	不锈钢	不锈钢 316	No
CBPS0860	25mm	800mm	600mm	不锈钢	不锈钢 304	No
CBPS0860-316	25mm	800mm	600mm	不锈钢	不锈钢 316	No
CBPS1040	25mm	1000mm	400mm	不锈钢	不锈钢 304	No
CBPS1040-316	25mm	1000mm	400mm	不锈钢	不锈钢 316	No
CBPS1050	25mm	1000mm	500mm	不锈钢	不锈钢 304	No

物料号	高度	宽度	深度	外壳材料	材料	快速发货
CBPS1050-316	25mm	1000mm	500mm	不锈钢	不锈钢 316	No
CBPS1060	25mm	1000mm	600mm	不锈钢	不锈钢 304	No
CBPS1060-316	25mm	1000mm	600mm	不锈钢	不锈钢 316	No

其他产品详情

For enclosures 1200 mm & 1600 mm wide use 2 x 600 mm & 2 x 800 mm wide bottom plates.

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE