


Switch Disconnecter, WO60

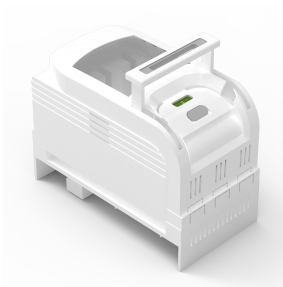

Spring controlled switch disconnecter without fuses.

工业标准

IEC
VDE
DNV-GL

功能

Description: 3-pole switch disconnecter. With multifunction handle (snap action switch mechanism). Connection at the bottom.

Rated voltage: 690 V

For busbars: 12, 15, 20, 25, 30 × 5, 10

Power dissipation at 80% load: 26,7 W

Pack quantity: 1 pc.

Approvals: IEC, VDE, DNV GL

Connection at the bottom

Rated voltage: 690 V

For busbars: 12, 15, 20, 25, 30 × 5, 10

Power dissipation at 80% load: 26,7 W

技术参数

Table 1/1

物料号	高度	宽度	深度	材料	完成	颜色
33540	200mm	106mm	176mm	塑料, 钢	平滑	浅灰色

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE