


UL 灯触摸安全开关

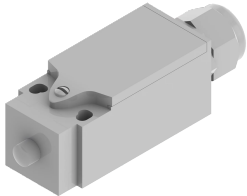

The Touch-Safe light switch is designed to be used with HOFFMAN light kits (AC and DC). It provides a UL listed touch-safe switch that can be used on many enclosure types and includes hardware for most applications. The light switch maintains enclosure overall rating up to UL 508A Type 4X or 12.

功能

经 UL 认证的触摸安全电线连接

包括可轻松安装到各种机柜类型的常用支架和五金件

线性执行器

螺丝夹子式接线

PG 11 cable gland entry

Wide operating temperature range: -13F to 158F (-25C to 70C)

Number of poles 2

技术参数

Table 1/1						
物料号	订货号	材料	完成	颜色	交流电压	直流电压
LDSWITCH	19278	塑料	平滑	灰色	250V	48V

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE