


Universal Connection Terminal, WO60

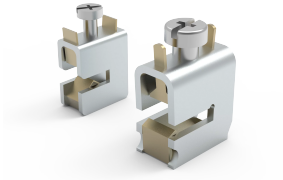

Terminals for connecting round conductors on to flat busbars
1,5 mm² to 120 mm².

工业标准

UL
CSA
GL
DNV-GL

功能

Description: Universal conductor terminal with integrated holding spring, a captive clamping screw, and open terminal space.

Rated voltage: 690 V

Approvals: CSA, UL, GL, DNV-GL

Indication of nominal cross-section and tightening torque is noted on the terminal

Can be used with cover cap 01590

Universal conductor terminal with integrated holding spring, a captive clamping screw, and open terminal space

Rated voltage: 690 V

技术参数

材料： 低碳钢
完成： 电镀

Table 1/1						
物料号	高度	宽度	深度	连接类型	最大电流	包装数量
01068	15mm	17mm	21mm	16 - 120 mm ²	440A	25
01284	7.5mm	7.5mm	21mm	1.5 - 16 mm ²	180A	100
01285	11mm	10.5mm	21mm	4 - 35 mm ²	270A	50
01287	14mm	14mm	21mm	16 - 70 mm ²	400A	25
01289	7.5mm	7.5mm	21mm	1.5 - 16 mm ²	180A	100
01203	15mm	17mm	21mm	16 - 120 mm ²	440A	25
01290	11mm	10.5mm	21mm	4 - 35 mm ²	270A	50
01292	14mm	14mm	21mm	16 - 70 mm ²	400A	25

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE