


Ventilated Top Cable Cover, CRB

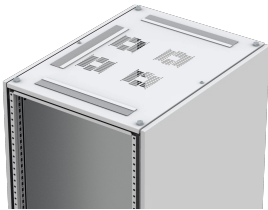

Up to four ventilation fans can be mounted on this roof plate, which means that the enclosure can be cooled in incremental steps, depending on the number of fans fitted. Brushes fitted to the cable openings allow for different cable diameters to be installed easily.

功能

Description: For cable entry on three sides in combination with ventilation. Cable openings provided with brushes. To mount closing plates DFC or inside mounting of (maximum 4) DFN01 ventilation fans.

Material: 1.5 mm steel plate.

Finish: RAL 7035 structured powder coating.

Pack quantity: 1 piece with brushes and mounting accessories.

Mounting requirements: Add DFN ventilation fans or DFC closing plates.

The brushes fitted to the cable openings allow different cable diameters to be installed in the field at the same time

It is recommended to install exhaust filters in the bottom of the enclosure to let air circulate properly

The cut-outs must be covered by either ventilation fans, DFN, or cover plates, DFC, depending on the amount of cooling required

For cable entry on three sides in combination with ventilation

Cable openings provided with brushes

To mount closing plates DFC or inside mounting of (maximum 4) DFN01 ventilation fans

Mounting requirements: Add DFN ventilation fans or DFC closing plates

技术参数

厚度: 1.5mm
颜色: 浅灰色
材料: 低碳钢
完成: 粉末涂层
颜色代码: RAL 7035

Table 1/1						
物料号	高度	宽度	深度	电缆入口数量	外壳材料	快速发货
CRB0808R5	17mm	800mm	800mm	6	低碳钢	No
CRB0806R5	17mm	800mm	600mm	4	低碳钢	No
CRB0608R5	17mm	600mm	800mm	6	低碳钢	No
CRB0606R5	17mm	600mm	600mm	4	低碳钢	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE