


Vertical Plug-In Busbar Supports For Power Distribution, MSVH

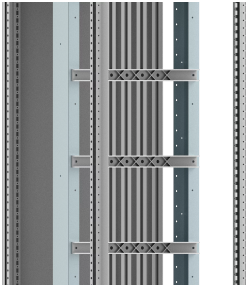

These vertical plug-in distribution busbar supports, MSVH, should be mounted on the enclosure behind the plug-in cover. They are available of the shelf and tested according to IEC 61439.

功能

Description: Busbar supports up to 1600A to be mounted vertically behind the plug-in compartments. Rated short-time withstand current up to 35KA with rear supports and up to 50KA with rear and front supports. Mounts to the vertical profiles included in the rear cover plate for plugin sections MSSB.

Material: Polycarbonate reinforced with 10% of glass material.

Delivery: 4 busbar support with mounting material.

The supports should be mounted onto the plug-in system vertical profiles (MSSB)

Plug-in busbars (MSBS), must be used in conjunction with these supports

Busbar supports up to 1600A to be mounted vertically behind the plug-in compartments

Rated short-time withstand current up to 35KA with rear supports and up to 50KA with rear and front supports

Mounts to the vertical profiles included in the rear cover plate for plugin sections MSSB

Delivery: 4 busbar support with mounting material

技术参数

Table 1/1						
物料号	高度	宽度	深度	外壳材料	产品系列	材料
MSVH1800	40mm	482mm	45mm	低碳钢	独立	聚碳酸酯
MSVH1800F	40mm	482mm	45mm	低碳钢	独立	聚碳酸酯
MSVH2000	40mm	482mm	45mm	低碳钢	独立	聚碳酸酯
MSVH2000F	40mm	482mm	45mm	低碳钢	独立	聚碳酸酯
MSVH2200	40mm	482mm	45mm	低碳钢	独立	聚碳酸酯
MSVH2200F	40mm	482mm	45mm	低碳钢	独立	聚碳酸酯

其他产品详情

*In: Rated current. *Ick: Rated short-time withstand current.

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE