

# A12 Standard Transition Coupler, Plain, Worldwide Design



## 认证



## 功能

Designed to splice different diameter bars where the second bar can be rotated and is not restricted in its axial direction

Slim design maintains concrete cover

Installs quickly and easily

## 技术参数

|       |               |
|-------|---------------|
| 完成:   | 普通            |
| 材料:   | 钢             |
| 设计版本: | 全球 (全球可供货的材料) |

Table 1/2

| 物料号        | 钢筋尺寸, 公制     | 钢筋尺寸, 美国 | 钢筋尺寸, 加拿大 | 六角宽度 (W) | 直径 (Ø) | 长度 (L) |
|------------|--------------|----------|-----------|----------|--------|--------|
| EL1210A12N | 12 mm, 10 mm | #4, #3   |           | 17 mm    |        | 55mm   |
| EL1412A12N | 14 mm, 12 mm |          |           | 22 mm    |        | 57mm   |
| EL1612A12N | 16 mm, 12 mm | #5, #4   | 15M, 10M  | 22 mm    |        | 61mm   |
| EL1614A12N | 16 mm, 14 mm |          |           | 22 mm    |        | 64mm   |
| EL1410A12N | 14 mm, 10 mm |          |           | 22 mm    |        | 57mm   |
| EL1610A12N | 16 mm, 10 mm | #5, #3   |           | 22 mm    |        | 61mm   |
| EL1810A12N | 18 mm, 10 mm |          |           | 27 mm    |        | 66mm   |
| EL1812A12N | 18 mm, 12 mm |          |           | 27 mm    |        | 66mm   |
| EL1814A12N | 18 mm, 14 mm |          |           | 27 mm    |        | 69mm   |
| EL1816A12N | 18 mm, 16 mm |          |           | 27 mm    |        | 71mm   |
| EL2012A12N | 20 mm, 12 mm | #6, #4   | 20M, 10M  | 27 mm    |        | 74mm   |
| EL2010A12N | 20 mm, 10 mm | #6, #3   |           | 27 mm    |        | 74mm   |
| EL2014A12N | 20 mm, 14 mm |          |           | 27 mm    |        | 77mm   |
| EL2016A12N | 20 mm, 16 mm | #6, #5   | 20M, 15M  | 27 mm    |        | 80mm   |
| EL2018A12N | 20 mm, 18 mm |          |           | 27 mm    |        | 85mm   |
| EL2212A12N | 22 mm, 12 mm | #7, #4   |           | 30 mm    |        | 77mm   |

| 物料号        | 钢筋尺寸, 公制     | 钢筋尺寸, 美国 | 钢筋尺寸, 加拿大 | 六角宽度 (W) | 直径 (Ø) | 长度 (L) |
|------------|--------------|----------|-----------|----------|--------|--------|
| EL2210A12N | 22 mm, 10 mm | #7, #3   |           | 30 mm    |        | 77mm   |
| EL2214A12N | 22 mm, 14 mm |          |           | 30 mm    |        | 80mm   |
| EL2216A12N | 22 mm, 16 mm | #7, #5   |           | 30 mm    |        | 83mm   |
| EL2218A12N | 22 mm, 18 mm |          |           | 30 mm    |        | 87mm   |
| EL2220A12N | 22 mm, 20 mm | #7, #6   |           | 30 mm    |        | 95mm   |
| EL2512A12N | 25 mm, 12 mm | #8, #4   | 25M, 10M  |          | 35 mm  | 81mm   |
| EL2510A12N | 25 mm, 10 mm | #8, #3   |           |          | 35 mm  | 81mm   |
| EL2514A12N | 25 mm, 14 mm |          |           |          | 35 mm  | 83mm   |
| EL2516A12N | 25 mm, 16 mm | #8, #5   | 25M, 15M  |          | 35 mm  | 86mm   |
| EL2518A12N | 25 mm, 18 mm |          |           |          | 35 mm  | 90mm   |
| EL2522A12N | 25 mm, 22 mm | #8, #7   |           |          | 35 mm  | 100mm  |
| EL2520A12N | 25 mm, 20 mm | #8, #6   | 25M, 20M  |          | 35 mm  | 98mm   |
| EL2814A12N | 28 mm, 14 mm |          |           |          | 40 mm  | 86mm   |
| EL2816A12N | 28 mm, 16 mm | #9, #5   | 30M, 15M  |          | 40 mm  | 88mm   |
| EL2818A12N | 28 mm, 18 mm |          |           |          | 40 mm  | 93mm   |
| EL3016A12N | 30 mm, 16 mm |          |           |          | 40 mm  | 99mm   |

| 物料号        | 钢筋尺寸, 公制     | 钢筋尺寸, 美国 | 钢筋尺寸, 加拿大 | 六角宽度 (W) | 直径 (Ø) | 长度 (L) |
|------------|--------------|----------|-----------|----------|--------|--------|
| EL2825A12N | 28 mm, 25 mm | #9, #8   | 30M, 25M  |          | 40 mm  | 104mm  |
| EL3028A12N | 30 mm, 28 mm |          |           |          | 40 mm  | 117mm  |
| EL2820A12N | 28 mm, 20 mm | #9, #6   | 30M, 20M  |          | 40 mm  | 101mm  |
| EL2822A12N | 28 mm, 22 mm | #9, #7   |           |          | 40 mm  | 103mm  |
| EL3018A12N | 30 mm, 18 mm |          |           |          | 40 mm  | 103mm  |
| EL3025A12N | 30 mm, 25 mm |          |           |          | 40 mm  | 115mm  |
| EL3020A12N | 30 mm, 20 mm |          |           |          | 40 mm  | 110mm  |
| EL3022A12N | 30 mm, 22 mm |          |           |          | 40 mm  | 113mm  |
| EL3216A12N | 32 mm, 16 mm | #10, #5  |           |          | 45 mm  | 92mm   |
| EL3218A12N | 32 mm, 18 mm |          |           |          | 45 mm  | 98mm   |
| EL3228A12N | 32 mm, 28 mm | #10, #9  |           |          | 45 mm  | 110mm  |
| EL3432A12N | 34 mm, 32 mm |          |           |          | 50 mm  | 123mm  |
| EL4038A12N | 40 mm, 38 mm |          |           |          | 55 mm  | 133mm  |
| EL3632A12N | 36 mm, 32 mm | #11, #10 |           |          | 50 mm  | 120mm  |
| EL3836A12N | 38 mm, 36 mm | #12, #11 |           |          | 55 mm  | 128mm  |
| EL3634A12N | 36 mm, 34 mm |          |           |          | 50 mm  | 130mm  |

| 物料号        | 钢筋尺寸, 公制     | 钢筋尺寸, 美国 | 钢筋尺寸, 加拿大 | 六角宽度 (W) | 直径 (Ø) | 长度 (L) |
|------------|--------------|----------|-----------|----------|--------|--------|
| EL4036A12N | 40 mm, 36 mm |          |           |          | 55 mm  | 132mm  |
| EL3225A12N | 32 mm, 25 mm | #10, #8  |           |          | 45 mm  | 109mm  |
| EL3230A12N | 32 mm, 30 mm |          |           |          | 45 mm  | 120mm  |
| EL3428A12N | 34 mm, 28 mm |          |           |          | 50 mm  | 120mm  |
| EL3832A12N | 38 mm, 32 mm |          |           |          | 55 mm  | 122mm  |
| EL3220A12N | 32 mm, 20 mm | #10, #6  |           |          | 45 mm  | 105mm  |
| EL3430A12N | 34 mm, 30 mm |          |           |          | 50 mm  | 131mm  |
| EL3834A12N | 38 mm, 34 mm |          |           |          | 55 mm  | 132mm  |
| EL4032A12N | 40 mm, 32 mm |          |           |          | 55 mm  | 126mm  |
| EL4034A12N | 40 mm, 34 mm |          |           |          | 55 mm  | 136mm  |
| EL3222A12N | 32 mm, 22 mm | #10, #7  |           |          | 45 mm  | 107mm  |
| EL3628A12N | 36 mm, 28 mm | #11, #9  | 35M, 30M  |          | 50 mm  | 118mm  |
| EL3630A12N | 36 mm, 30 mm |          |           |          | 50 mm  | 128mm  |
| EL3425A12N | 34 mm, 25 mm |          |           |          | 50 mm  | 119mm  |
| EL3828A12N | 38 mm, 28 mm | #12, #9  |           |          | 55 mm  | 119mm  |
| EL3625A12N | 36 mm, 25 mm | #11, #8  | 35M, 25M  |          | 50 mm  | 116mm  |

| 物料号          | 钢筋尺寸, 公制     | 钢筋尺寸, 美国 | 钢筋尺寸, 加拿大 | 六角宽度 (W) | 直径 (Ø) | 长度 (L) |
|--------------|--------------|----------|-----------|----------|--------|--------|
| EL3830A12N   | 38 mm, 30 mm |          |           |          | 55 mm  | 130mm  |
| EL4028A12N   | 40 mm, 28 mm |          |           |          | 55 mm  | 123mm  |
| EL4030A12N   | 40 mm, 30 mm |          |           |          | 55 mm  | 134mm  |
| EL3422A12N   | 34 mm, 22 mm |          |           |          | 50 mm  | 117mm  |
| EL3825A12N   | 38 mm, 25 mm | #12, #8  |           |          | 55 mm  | 118mm  |
| EL4025A12N   | 40 mm, 25 mm |          |           |          | 55 mm  | 122mm  |
| EL3420A12N   | 34 mm, 20 mm |          |           |          | 50 mm  | 115mm  |
| EL3622A12N   | 36 mm, 22 mm | #11, #7  |           |          | 50 mm  | 114mm  |
| EL3620A12N   | 36 mm, 20 mm | #11, #6  | 35M, 20M  |          | 50 mm  | 112mm  |
| EL43T36A12N  | 43 mm, 36 mm | #14, #11 | 45M, 35M  |          | 60 mm  | 148mm  |
| EL50T40A12N  | 50 mm, 40 mm |          |           |          | 70 mm  | 157mm  |
| EL50T38A12N  | 50 mm, 38 mm |          |           |          | 70 mm  | 154mm  |
| EL50T36A12N  | 50 mm, 36 mm |          |           |          | 70 mm  | 153mm  |
| EL50T32A12N  | 50 mm, 32 mm |          |           |          | 70 mm  | 147mm  |
| EL50T34A12N  | 50 mm, 34 mm |          |           |          | 70 mm  | 156mm  |
| EL57T43TA12N | 57 mm, 43 mm | #18, #14 | 55M, 45M  |          | 80 mm  | 184mm  |

Table 2/2

| 物料号        | 杆深 1 (BD1) | 杆深 2 (BD2) | 杆间隙 (BG) | 单位重量    | 认证                                                                                                                      |
|------------|------------|------------|----------|---------|-------------------------------------------------------------------------------------------------------------------------|
| EL1210A12N | 19mm       | 18mm       | 18mm     | 0.08 kg | nVent LENTON EPD - Product Specific, RISE, ITB, DIBt, Kontrollrådet                                                     |
| EL1412A12N | 21mm       | 19mm       | 17mm     | 0.14 kg | CARES, Kontrollrådet, nVent LENTON EPD - Product Specific, RISE, ITB, KOMO, Kontrollrådet, DIBt                         |
| EL1612A12N | 24mm       | 19mm       | 18mm     | 0.14 kg | CARES, KOMO, nVent LENTON EPD - Product Specific, ITB, LA City Approval, Kontrollrådet, IAPMO®-UES, Kontrollrådet, RISE |
| EL1614A12N | 24mm       | 21mm       | 19mm     | 0.14 kg | ITB, DIBt, Kontrollrådet, Kontrollrådet, RISE, KOMO, CARES, nVent LENTON EPD - Product Specific                         |
| EL1410A12N | 21mm       | 18mm       | 18mm     | 0.15 kg | Kontrollrådet, nVent LENTON EPD - Product Specific, ITB                                                                 |
| EL1610A12N | 24mm       | 18mm       | 19mm     | 0.15 kg | nVent LENTON EPD - Product Specific, ITB, Kontrollrådet                                                                 |

| 物料号        | 杆深 1 (BD1) | 杆深 2 (BD2) | 杆间隙 (BG) | 单位重量    | 认证                                                                                                                                                    |
|------------|------------|------------|----------|---------|-------------------------------------------------------------------------------------------------------------------------------------------------------|
| EL1810A12N | 29mm       | 18mm       | 19mm     | 0.25 kg | nVent LENTON<br>EPD - Product<br>Specific, ITB                                                                                                        |
| EL1812A12N | 29mm       | 19mm       | 18mm     | 0.25 kg | nVent LENTON<br>EPD - Product<br>Specific, ITB                                                                                                        |
| EL1814A12N | 29mm       | 21mm       | 19mm     | 0.25 kg | nVent LENTON<br>EPD - Product<br>Specific, ITB                                                                                                        |
| EL1816A12N | 29mm       | 24mm       | 18mm     | 0.25 kg | ITB, nVent<br>LENTON EPD -<br>Product Specific                                                                                                        |
| EL2012A12N | 35mm       | 19mm       | 20mm     | 0.26 kg | RISE, KOMO,<br>CARES, nVent<br>LENTON EPD -<br>Product Specific,<br>Kontrollrådet,<br>ITB, Kontrollrådet                                              |
| EL2010A12N | 35mm       | 18mm       | 21mm     | 0.27 kg | nVent LENTON<br>EPD - Product<br>Specific,<br>Kontrollrådet, ITB                                                                                      |
| EL2014A12N | 35mm       | 21mm       | 21mm     | 0.27 kg | nVent LENTON<br>EPD - Product<br>Specific,<br>Kontrollrådet,<br>ITB,<br>Kontrollrådet,<br>KOMO, RISE,<br>CARES                                        |
| EL2016A12N | 35mm       | 24mm       | 21mm     | 0.27 kg | nVent LENTON<br>EPD - Product<br>Specific, DIBt, LA<br>City Approval,<br>Kontrollrådet,<br>ITB, KOMO,<br>Kontrollrådet,<br>CARES, RISE,<br>IAPMO®-UES |



| 物料号        | 杆深 1 (BD1) | 杆深 2 (BD2) | 杆间隙 (BG) | 单位重量    | 认证                                                                                        |
|------------|------------|------------|----------|---------|-------------------------------------------------------------------------------------------|
| EL2018A12N | 35mm       | 29mm       | 21mm     | 0.27 kg | ITB, nVent LENTON EPD - Product Specific                                                  |
| EL2212A12N | 37mm       | 19mm       | 21mm     | 0.34 kg | nVent LENTON EPD - Product Specific, ITB                                                  |
| EL2210A12N | 37mm       | 18mm       | 22mm     | 0.35 kg | nVent LENTON EPD - Product Specific, ITB                                                  |
| EL2214A12N | 37mm       | 21mm       | 22mm     | 0.35 kg | nVent LENTON EPD - Product Specific, ITB                                                  |
| EL2216A12N | 37mm       | 24mm       | 22mm     | 0.35 kg | nVent LENTON EPD - Product Specific, ITB                                                  |
| EL2218A12N | 37mm       | 29mm       | 21mm     | 0.36 kg | nVent LENTON EPD - Product Specific, ITB                                                  |
| EL2220A12N | 37mm       | 35mm       | 23mm     | 0.38 kg | nVent LENTON EPD - Product Specific, LA City Approval, IAPMO®-UES, ITB                    |
| EL2512A12N | 40mm       | 19mm       | 22mm     | 0.43 kg | ITB, Kontrollrådet, KOMO, CARES, nVent LENTON EPD - Product Specific, RISE, Kontrollrådet |
| EL2510A12N | 40mm       | 18mm       | 23mm     | 0.44 kg | nVent LENTON EPD - Product Specific, Kontrollrådet                                        |

| 物料号        | 杆深 1 (BD1) | 杆深 2 (BD2) | 杆间隙 (BG) | 单位重量    | 认证                                                                                                                |
|------------|------------|------------|----------|---------|-------------------------------------------------------------------------------------------------------------------|
| EL2514A12N | 40mm       | 21mm       | 22mm     | 0.44 kg | ITB,<br>Kontrollrådet,<br>KOMO, CARES,<br>nVent LENTON<br>EPD - Product<br>Specific, RISE,<br>Kontrollrådet       |
| EL2516A12N | 40mm       | 24mm       | 22mm     | 0.45 kg | KOMO, CARES,<br>nVent LENTON<br>EPD - Product<br>Specific, RISE,<br>Kontrollrådet,<br>ITB, Kontrollrådet          |
| EL2518A12N | 40mm       | 29mm       | 21mm     | 0.47 kg | nVent LENTON<br>EPD - Product<br>Specific, ITB                                                                    |
| EL2522A12N | 40mm       | 37mm       | 23mm     | 0.49 kg | LA City Approval,<br>ITB, IAPMO®-UES,<br>nVent LENTON<br>EPD - Product<br>Specific                                |
| EL2520A12N | 40mm       | 35mm       | 23mm     | 0.5 kg  | nVent LENTON<br>EPD - Product<br>Specific, CARES,<br>RISE,<br>Kontrollrådet,<br>DIBt, ITB, KOMO,<br>Kontrollrådet |
| EL2814A12N | 42mm       | 21mm       | 23mm     | 0.61 kg | nVent LENTON<br>EPD - Product<br>Specific, KOMO,<br>ITB                                                           |
| EL2816A12N | 42mm       | 24mm       | 22mm     | 0.62 kg | KOMO, nVent<br>LENTON EPD -<br>Product Specific,<br>ITB                                                           |
| EL2818A12N | 42mm       | 29mm       | 22mm     | 0.65 kg | nVent LENTON<br>EPD - Product<br>Specific, ITB                                                                    |

| 物料号        | 杆深 1 (BD1) | 杆深 2 (BD2) | 杆间隙 (BG) | 单位重量    | 认证                                                                                                       |
|------------|------------|------------|----------|---------|----------------------------------------------------------------------------------------------------------|
| EL3016A12N | 52mm       | 24mm       | 23mm     | 0.66 kg | nVent LENTON<br>EPD - Product<br>Specific                                                                |
| EL2825A12N | 42mm       | 40mm       | 22mm     | 0.67 kg | KOMO, LA City<br>Approval, nVent<br>LENTON EPD -<br>Product Specific,<br>IAPMO®-UES,<br>DIBt, ITB        |
| EL3028A12N | 52mm       | 42mm       | 23mm     | 0.68 kg | nVent LENTON<br>EPD - Product<br>Specific                                                                |
| EL2820A12N | 42mm       | 35mm       | 24mm     | 0.69 kg | ITB, KOMO, nVent<br>LENTON EPD -<br>Product Specific                                                     |
| EL2822A12N | 42mm       | 37mm       | 24mm     | 0.69 kg | ITB, nVent<br>LENTON EPD -<br>Product Specific                                                           |
| EL3018A12N | 52mm       | 29mm       | 22mm     | 0.69 kg | nVent LENTON<br>EPD - Product<br>Specific                                                                |
| EL3025A12N | 52mm       | 40mm       | 23mm     | 0.71 kg | nVent LENTON<br>EPD - Product<br>Specific                                                                |
| EL3020A12N | 52mm       | 35mm       | 23mm     | 0.73 kg | nVent LENTON<br>EPD - Product<br>Specific                                                                |
| EL3022A12N | 52mm       | 37mm       | 24mm     | 0.73 kg | nVent LENTON<br>EPD - Product<br>Specific                                                                |
| EL3216A12N | 45mm       | 24mm       | 23mm     | 0.81 kg | nVent LENTON<br>EPD - Product<br>Specific, CARES,<br>Kontrollrådet,<br>ITB, RISE, KOMO,<br>Kontrollrådet |

| 物料号        | 杆深 1 (BD1) | 杆深 2 (BD2) | 杆间隙 (BG) | 单位重量    | 认证                                                                                        |
|------------|------------|------------|----------|---------|-------------------------------------------------------------------------------------------|
| EL3218A12N | 45mm       | 29mm       | 24mm     | 0.86 kg | ITB, nVent LENTON EPD - Product Specific                                                  |
| EL3228A12N | 45mm       | 42mm       | 23mm     | 0.88 kg | IAPMO®-UES, ITB, KOMO, LA City Approval, DIBt, nVent LENTON EPD - Product Specific        |
| EL3432A12N | 55mm       | 45mm       | 23mm     | 1.24 kg | nVent LENTON EPD - Product Specific                                                       |
| EL4038A12N | 57mm       | 53mm       | 23mm     | 1.47 kg | nVent LENTON EPD - Product Specific                                                       |
| EL3632A12N | 52mm       | 45mm       | 23mm     | 1.15 kg | IAPMO®-UES, nVent LENTON EPD - Product Specific, LA City Approval                         |
| EL3836A12N | 53mm       | 52mm       | 23mm     | 1.51 kg | nVent LENTON EPD - Product Specific                                                       |
| EL3634A12N | 52mm       | 55mm       | 23mm     | 1.23 kg | nVent LENTON EPD - Product Specific                                                       |
| EL4036A12N | 57mm       | 52mm       | 23mm     | 1.5 kg  | nVent LENTON EPD - Product Specific                                                       |
| EL3225A12N | 45mm       | 40mm       | 24mm     | 0.91 kg | nVent LENTON EPD - Product Specific, CARES, Kontrollrådet, ITB, Kontrollrådet, KOMO, RISE |


| 物料号        | 杆深 1 (BD1) | 杆深 2 (BD2) | 杆间隙 (BG) | 单位重量    | 认证                                                                                                       |
|------------|------------|------------|----------|---------|----------------------------------------------------------------------------------------------------------|
| EL3230A12N | 45mm       | 52mm       | 23mm     | 0.95 kg | nVent LENTON<br>EPD - Product<br>Specific                                                                |
| EL3428A12N | 55mm       | 42mm       | 23mm     | 1.28 kg | nVent LENTON<br>EPD - Product<br>Specific                                                                |
| EL3832A12N | 53mm       | 45mm       | 24mm     | 1.51 kg | nVent LENTON<br>EPD - Product<br>Specific                                                                |
| EL3220A12N | 45mm       | 35mm       | 25mm     | 0.92 kg | RISE, KOMO,<br>Kontrollrådet,<br>CARES, nVent<br>LENTON EPD -<br>Product Specific,<br>Kontrollrådet, ITB |
| EL3430A12N | 55mm       | 52mm       | 24mm     | 1.37 kg | nVent LENTON<br>EPD - Product<br>Specific                                                                |
| EL3834A12N | 53mm       | 55mm       | 24mm     | 1.62 kg | nVent LENTON<br>EPD - Product<br>Specific                                                                |
| EL4032A12N | 57mm       | 45mm       | 24mm     | 1.5 kg  | Kontrollrådet,<br>CARES, nVent<br>LENTON EPD -<br>Product Specific,<br>RISE, ITB, DIBt                   |
| EL4034A12N | 57mm       | 55mm       | 24mm     | 1.61 kg | nVent LENTON<br>EPD - Product<br>Specific                                                                |
| EL3222A12N | 45mm       | 37mm       | 25mm     | 0.93 kg | nVent LENTON<br>EPD - Product<br>Specific, ITB                                                           |
| EL3628A12N | 52mm       | 42mm       | 24mm     | 1.19 kg | nVent LENTON<br>EPD - Product<br>Specific                                                                |

| 物料号        | 杆深 1 (BD1) | 杆深 2 (BD2) | 杆间隙 (BG) | 单位重量    | 认证                                                                               |
|------------|------------|------------|----------|---------|----------------------------------------------------------------------------------|
| EL3630A12N | 52mm       | 52mm       | 24mm     | 1.28 kg | nVent LENTON<br>EPD - Product<br>Specific                                        |
| EL3425A12N | 55mm       | 40mm       | 24mm     | 1.31 kg | nVent LENTON<br>EPD - Product<br>Specific                                        |
| EL3828A12N | 53mm       | 42mm       | 24mm     | 1.54 kg | nVent LENTON<br>EPD - Product<br>Specific                                        |
| EL3625A12N | 52mm       | 40mm       | 24mm     | 1.22 kg | nVent LENTON<br>EPD - Product<br>Specific                                        |
| EL3830A12N | 53mm       | 52mm       | 25mm     | 1.67 kg | nVent LENTON<br>EPD - Product<br>Specific                                        |
| EL4028A12N | 57mm       | 42mm       | 24mm     | 1.54 kg | ITB, nVent<br>LENTON EPD -<br>Product Specific                                   |
| EL4030A12N | 57mm       | 52mm       | 25mm     | 1.66 kg | nVent LENTON<br>EPD - Product<br>Specific                                        |
| EL3422A12N | 55mm       | 37mm       | 25mm     | 1.32 kg | nVent LENTON<br>EPD - Product<br>Specific                                        |
| EL3825A12N | 53mm       | 40mm       | 25mm     | 1.56 kg | nVent LENTON<br>EPD - Product<br>Specific                                        |
| EL4025A12N | 57mm       | 40mm       | 25mm     | 1.56 kg | ITB, nVent<br>LENTON EPD -<br>Product Specific,<br>CARES, RISE,<br>Kontrollrådet |
| EL3420A12N | 55mm       | 35mm       | 25mm     | 1.31 kg | nVent LENTON<br>EPD - Product<br>Specific                                        |

| 物料号          | 杆深 1 (BD1) | 杆深 2 (BD2) | 杆间隙 (BG) | 单位重量    | 认证                                                                            |
|--------------|------------|------------|----------|---------|-------------------------------------------------------------------------------|
| EL3622A12N   | 52mm       | 37mm       | 25mm     | 1.22 kg | nVent LENTON<br>EPD - Product<br>Specific                                     |
| EL3620A12N   | 52mm       | 35mm       | 25mm     | 1.22 kg | nVent LENTON<br>EPD - Product<br>Specific                                     |
| EL43T36A12N  | 66mm       | 52mm       | 30mm     | 2.1 kg  | LA City Approval,<br>IAPMO®-UES,<br>nVent LENTON<br>EPD - Product<br>Specific |
| EL50T40A12N  | 70mm       | 57mm       | 30mm     | 3.09 kg | CARES, nVent<br>LENTON EPD -<br>Product Specific                              |
| EL50T38A12N  | 70mm       | 53mm       | 31mm     | 3.06 kg | nVent LENTON<br>EPD - Product<br>Specific                                     |
| EL50T36A12N  | 70mm       | 52mm       | 31mm     | 3.08 kg | nVent LENTON<br>EPD - Product<br>Specific                                     |
| EL50T32A12N  | 70mm       | 45mm       | 32mm     | 3 kg    | CARES, nVent<br>LENTON EPD -<br>Product Specific                              |
| EL50T34A12N  | 70mm       | 55mm       | 31mm     | 3.22 kg | nVent LENTON<br>EPD - Product<br>Specific                                     |
| EL57T43TA12N | 83mm       | 66mm       | 35mm     | 4.87 kg | LA City Approval,<br>IAPMO®-UES,<br>nVent LENTON<br>EPD - Product<br>Specific |

## 其他产品详情

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

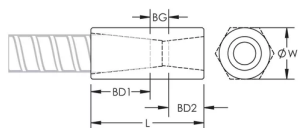

## 警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

### 北美

+1.800.753.9221  
，按 1 转客户服务  
，按 2 转技术支持

### 欧洲

荷兰：  
+31 800-0200135  
法国：  
+33 800 901 793

### 欧洲

德国：  
800 1890272  
其他国家/地区：  
+31 13 5835404

### 亚太地区

上海：  
+ 86 21 2412 1618/19  
悉尼：  
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE