


A2 Standard Coupler, Stainless Steel

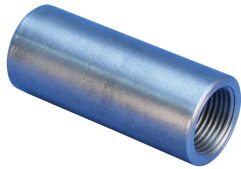

Stainless steel couplers are specified whenever corrosive environmental conditions combine with the need for high load-bearing strength. nVent LENTON stainless steel couplers are commonly used when the construction materials may come into contact with de-icing salts, salt water or marine environments. Typical applications include bridges and bridge decks.

功能

Designed to splice the same diameter bars where the second bar can be rotated and is not restricted in its axial direction

Slim design maintains concrete cover

Installs quickly and easily

Duplex 2205 stainless steel provides a unique combination of strength and corrosion resistance

技术参数

完成: 普通

材料: 双相不锈钢 2205 (EN 1.4462)

Table 1/2

物料号	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	直径 (Ø)	长度 (L)	杆深 (BD)
EL12A2SSN	12 mm	#4	10M	25 mm	41mm	15mm
EL16A2SSN	16 mm	#5	15M	25 mm	56mm	22mm
EL20A2SSN	20 mm	#6	20M	38 mm	71mm	28mm


物料号	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	直径 (Ø)	长度 (L)	杆深 (BD)
EL22A2SSN	22 mm	#7		38 mm	80mm	32mm
EL28A2SSN	28 mm	#9	30M	38 mm	91mm	38mm
EL25A2SSN	25 mm	#8	25M	38 mm	85mm	34mm
EL36A2SSN	36 mm	#11	35M	48 mm	101mm	43mm
EL32A2SSN	32 mm	#10		48 mm	96mm	40mm

Table 2/2

物料号	杆间隙 (BG)	单位重量
EL12A2SSN	11mm	0.14 kg
EL16A2SSN	12mm	0.16 kg
EL20A2SSN	15mm	0.25 kg
EL22A2SSN	16mm	0.34 kg
EL28A2SSN	15mm	0.49 kg
EL25A2SSN	17mm	0.53 kg
EL36A2SSN	15mm	1.01 kg
EL32A2SSN	16mm	0.82 kg

其他产品详情

 Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.



警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE