

B-Series Vertical Filler Material Kit



B-Series vertical filler material kits contain the following: Filler material, vertical packing, pouring basin ceramic guide tube and pouring basin crucible ceramic and disk. All filler material kits contain one-time use components that are sized to a specific sleeve, pouring basin and pouring basin crucible combination. Ordering filler material kits simplifies ordering, reduces order errors and helps ensure proper sizing of components.

功能

Simplifies ordering

All components are for one-time use

技术参数

Table 1/1

物料号	钢筋尺寸，公制	钢筋尺寸，美国	钢筋尺寸，加拿大
RBB1292B	38 mm	#12	
RBB14101B	43 mm	#14	45M
RBB1892B	57 mm	#18	55M
RBB592B	16 mm	#5	15M
RBB692B	20 mm	#6	20M
RBB792B	22 mm	#7	
RBB8101B	25 mm	#8	25M

物料号	钢筋尺寸，公制	钢筋尺寸，美国	钢筋尺寸，加拿大
RBB992B	28 mm	#9	30M
RBB1092B	32 mm	#10	
RBB11101B	36 mm	#11	35M


其他产品详情

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

Filler material kits are a component in splice kits. Care should be taken to avoid duplication of orders.

Components can also be purchased separately: (1) Filler Material, (2) Packing, (3) Pouring Basin Ceramic Guide Tube, and (4) Pouring Basin Ceramic Insert and Disk.

Filler Material Kit Components				
Filler Material Kit	Filler Material	Packing (2 Required)	Pouring Basin Ceramic Insert and Disk	Pouring Basin Ceramic Guide Tube
RBB592B	RBF40	RBS35477	RBS5037	RBS5038
RBB692B	RBF40	RBS35477	RBS5037	RBS5038
RBB792B	RBF50	RBS35478	RBS5037	RBS5038
RBB8101B	RBF55	RBS354710	RBS5037	RBS5038
RBB992B	RBF80	RBS354711	RBS5037	RBS5038
RBB1092B	RBF90	RBS354712	RBS5037	RBS5038
RBB11101B	RBF105	RBS354712	RBS5037	RBS5038
RBB1292B	RBF125	RBS354715	RBS5037	RBS5038
RBB14101B	RBF180	RBS354715	RBS5037	RBS5039
RBB1892B	RBF220	RBS354720	RBS5037	RBS5039

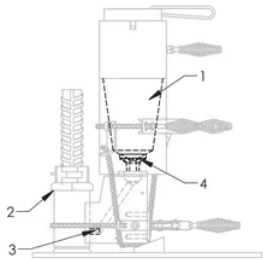

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE