

CFFP Tapered Plastic Screw-In Plug for A12, A22 and A32K Couplers



功能

Designed for use with the A12, A22 and A32K coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Durable mounting plates allow for easy attachment to forms

Color coded for the appropriate coupler size

技术参数

材料: 聚乙烯

Table 1/2

物料号	订货号	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	直径 (Ø)	高度 (H)
EL28CFFP	156070	28 mm	#9	30M	59 mm	23 mm
EL12CFFP	156010	12 mm	#4	10M	59 mm	23 mm
EL25CFFP	156060	25 mm	#8	25M	59 mm	23 mm


物料号	订货号	钢筋尺寸，公制	钢筋尺寸，美国	钢筋尺寸，加拿大	直径 (Ø)	高度 (H)
EL20CFFP	156050	20 mm	#6	20M	59 mm	23 mm
EL16CFFP	156030	16 mm	#5	15M	59 mm	23 mm
EL14CFFP	156020	14 mm			59 mm	23 mm

Table 2/2		
物料号	订货号	颜色
EL28CFFP	156070	黑色
EL12CFFP	156010	红色
EL25CFFP	156060	红色
EL20CFFP	156050	黄色
EL16CFFP	156030	黑色
EL14CFFP	156020	绿色

其他产品详情

EL12CFFP and EL16CFFP can also be used on the A2 coupler families.

图

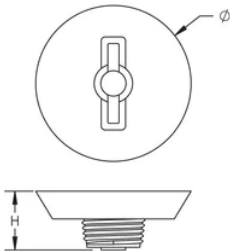

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE