

One-Piece Flange Coupler, 16 mm, #5, 15M

物料号

EL16SANSP004



One-piece flange couplers are ideal for eliminating protruding dowel bars in segmental pour applications. The flange side of the coupler is typically tack or seal welded to cast-in-place structural steel walls commonly found in most modern nuclear reactor designs.

功能

Designed to splice the same diameter bars where the second bar can be rotated and is not restricted in its axial direction

Tack welding allows the coupler to be used for positioning of a bent bar on the first bar

Installs quickly and easily

产品属性

材料: 钢

完成: 普通

钢筋尺寸, 公制: 16 mm

钢筋尺寸, 美国: #5

钢筋尺寸, 加拿大: 15M

直径 1 (Ø1): 40 mm

直径 2 (Ø2): 25 mm

长度 1 (L1): 56 mm

长度 2 (L2): 40 mm

杆深 (BD): 22mm

杆间隙 (BG): 12mm

单位重量: 0.23 kg


设计符合: AASHTO;ABNT NBR 8548:1984;ACI 318 1 型 (125% 指定屈服强度) ;ACI 318 2 型 (指定抗拉强度) ;ACI 349;ACI 359;AS3600

包装数量: 80

其他产品详情

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

图

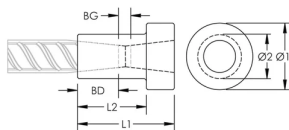

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE