

P9J Weldable Position Coupler, 28 mm, #9, 30M

物料号

EL28P9J



功能

Designed for connecting reinforcing bar perpendicular to structural steel sections or plates when the mating bar cannot be rotated and is free to move in its axial direction

Ideal for connecting hooked reinforcing bar to structural steel elements

Internally taper threaded on one end, with the other end prepared for welding

Machined from weldable grades of steel

产品属性

材料: 钢

完成: 普通

100% 美国国内内容: 是

钢筋尺寸, 公制: 28 mm

钢筋尺寸, 美国: #9

钢筋尺寸, 加拿大: 30M

直径 1 (Ø1): 76 mm


直径 2 (Ø2): 64 mm

长度 1 (L1): 114 mm
长度 2 (L2): 121 mm
杆深 (BD): 38mm
联轴器主体 (CB): 73mm
单位重量: 2.72 kg
设计符合: AASHTO;ABNT NBR 8548:1984;ACI 318 1 型（125% 指定屈服强度）;ACI 318 2 型（指定抗拉强度）;ACI 349;ACI 359;AS3600
包装数量: 6

其他产品详情

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

图

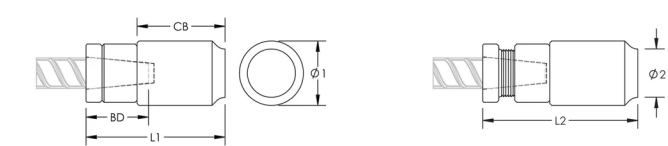

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE