

ELFB Taper Form Bolt



The ELFB taper bolt is used to firmly attach a nVent LENTON taper-threaded coupler onto formwork in precast and cast-in-place construction. This reusable form saving accessory allows forms to be pre-drilled with the correct spacing of the reinforcing steel, which speeds construction and allows the forms to be re-used on repetitive construction elements. This system can be used in conjunction with coupler boxes to eliminate the use of bend-out-boxes and also helps eliminate protruding dowel bars.

The screw-in bolt is designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour. The bolt eliminates the need for form saving plates and simplifies the use of standard couplers in form saving applications.☒

功能

Multiple lengths available depending on form thickness

Used in both form saving and coupler box applications

Bar end protector included to protect the nVent LENTON taper thread

Durable, re-usable and long lasting

Saves time and money

技术参数

材料: 钢

Table 1/2

物料号	包含螺母	形状厚度 (FT)	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	长度 (L)
ELFB10X003	否	3 mm	10 mm	#3		21mm

物料号	包含螺母	形状厚度 (FT)	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	长度 (L)
ELFB12X003	否	3 mm	12 mm	#4	10M	21mm
ELFB10X020	是	3 - 20 mm	10 mm	#3		55mm
ELFB12X010	否	3 - 10 mm	12 mm	#4	10M	28mm
ELFB14X003	否	3 mm	14 mm			25mm
ELFB10X040	是	3 - 40 mm	10 mm	#3		75mm
ELFB12X020	是	3 - 20 mm	12 mm	#4	10M	60mm
ELFB16X003	否	3 mm	16 mm	#5	15M	28mm
ELFB18X003	否	3 mm	18 mm			33mm
ELFB20X003	否	3 mm	20 mm	#6	20M	38mm
ELFB22X003	否	3 mm	22 mm	#7		40mm
ELFB25X003	否	3 mm	25 mm	#8	25M	43mm
ELFB28X003	否	3 mm	28 mm	#9	30M	45mm
ELFB30X003	否	3 mm	30 mm			55mm
ELFB32X003	否	3 mm	32 mm	#10		49mm
ELFB34X003	否	3 mm	34 mm			59mm
ELFB36X003	否	3 mm	36 mm	#11	35M	56mm

物料号	包含螺母	形状厚度 (FT)	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	长度 (L)
ELFB16X010	否	3 - 10 mm	16 mm	#5	15M	35mm
ELFB20X010	否	3 - 10 mm	20 mm	#6	20M	45mm
ELFB14X020	是	3 - 20 mm	14 mm			65mm
ELFB16X020	是	3 - 20 mm	16 mm	#5	15M	70mm
ELFB18X020	是	3 - 20 mm	18 mm			75mm
ELFB20X020	是	3 - 20 mm	20 mm	#6	20M	90mm
ELFB22X020	是	3 - 20 mm	22 mm	#7		90mm
ELFB25X020	是	3 - 20 mm	25 mm	#8	25M	100mm
ELFB28X020	是	3 - 20 mm	28 mm	#9	30M	100mm
ELFB30X020	是	3 - 20 mm	30 mm			110mm
ELFB32X020	是	3 - 20 mm	32 mm	#10		110mm
ELFB34X020	是	3 - 20 mm	34 mm			120mm
ELFB36X020	是	3 - 20 mm	36 mm	#11	35M	115mm
ELFB12X040	是	3 - 40 mm	12 mm	#4	10M	80mm
ELFB14X040	是	3 - 40 mm	14 mm			85mm
ELFB16X040	是	3 - 40 mm	16 mm	#5	15M	90mm

物料号	包含螺母	形状厚度 (FT)	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	长度 (L)
ELFB18X040	是	3 - 40 mm	18 mm			95mm
ELFB20X040	是	3 - 40 mm	20 mm	#6	20M	105mm
ELFB22X040	是	3 - 40 mm	22 mm	#7		110mm
ELFB25X040	是	3 - 40 mm	25 mm	#8	25M	115mm
ELFB28X040	是	3 - 40 mm	28 mm	#9	30M	120mm
ELFB30X040	是	3 - 40 mm	30 mm			130mm
ELFB32X040	是	3 - 40 mm	32 mm	#10		130mm
ELFB34X040	是	3 - 40 mm	34 mm			140mm
ELFB36X040	是	3 - 40 mm	36 mm	#11	35M	135mm

Table 2/2				
物料号	外径 (OD)	插座宽度 (SW)	单位重量	垫圈数量
ELFB10X003	12 mm	18mm	0.04 kg	2
ELFB12X003	14 mm	21mm	0.06 kg	2
ELFB10X020	12 mm	18mm	0.08 kg	1
ELFB12X010	14 mm	21mm	0.08 kg	4
ELFB14X003	16 mm	24mm	0.09 kg	2
ELFB10X040	12 mm	18mm	0.1 kg	1

物料号	外径 (OD)	插座宽度 (SW)	单位重量	垫圈数量
ELFB12X020	14 mm	21mm	0.12 kg	1
ELFB16X003	20 mm	30mm	0.14 kg	2
ELFB18X003	20 mm	30mm	0.17 kg	2
ELFB20X003	24 mm	36mm	0.27 kg	2
ELFB22X003	24 mm	36mm	0.29 kg	2
ELFB25X003	30 mm	46mm	0.52 kg	2
ELFB28X003	30 mm	46mm	0.55 kg	2
ELFB30X003	30 mm	46mm	0.71 kg	4
ELFB32X003	36 mm	55mm	0.92 kg	2
ELFB34X003	36 mm	55mm	1.16 kg	4
ELFB36X003	36 mm	55mm	1 kg	2
ELFB16X010	20 mm	30mm	0.2 kg	4
ELFB20X010	24 mm	36mm	0.36 kg	4
ELFB14X020	16 mm	24mm	0.17 kg	1
ELFB16X020	20 mm	30mm	0.3 kg	1
ELFB18X020	20 mm	30mm	0.32 kg	1
ELFB20X020	24 mm	36mm	0.54 kg	1

物料号	外径 (OD)	插座宽度 (SW)	单位重量	垫圈数量
ELFB22X020	24 mm	36mm	0.55 kg	1
ELFB25X020	30 mm	46mm	1 kg	1
ELFB28X020	30 mm	46mm	1.06 kg	1
ELFB30X020	30 mm	46mm	1.11 kg	1
ELFB32X020	36 mm	55mm	1.73 kg	1
ELFB34X020	36 mm	55mm	1.81 kg	1
ELFB36X020	36 mm	55mm	1.81 kg	1
ELFB12X040	14 mm	21mm	0.14 kg	1
ELFB14X040	16 mm	24mm	0.2 kg	1
ELFB16X040	20 mm	30mm	0.34 kg	1
ELFB18X040	20 mm	30mm	0.36 kg	1
ELFB20X040	24 mm	36mm	0.58 kg	1
ELFB22X040	24 mm	36mm	0.62 kg	1
ELFB25X040	30 mm	46mm	1.09 kg	1
ELFB28X040	30 mm	46mm	1.16 kg	1
ELFB30X040	30 mm	46mm	1.21 kg	1
ELFB32X040	36 mm	55mm	1.87 kg	1


物料号	外径 (OD)	插座宽度 (SW)	单位重量	垫圈数量
ELFB34X040	36 mm	55mm	1.95 kg	1
ELFB36X040	36 mm	55mm	1.95 kg	1

其他产品详情

Length dimension is for reference only.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

图

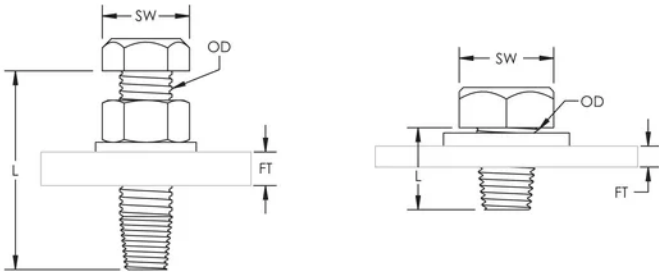

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE