

# End Alignment Fitting



End alignment fittings properly locate the sleeve onto the reinforcing steel. The fittings also retain the packing materials and hold them in place, which helps ensure a leak-free installation.

## 功能

Durable, re-usable and long lasting

Easily replaced if damaged

Split-collar design allows for easy installation and removal

## 技术参数

材料: 钢

Table 1/1

| 物料号         | 钢筋尺寸, 公制 | 钢筋尺寸, 美国 | 钢筋尺寸, 加拿大 | 高度 (H) | 直径 1 (Ø1) | 直径 2 (Ø2) |
|-------------|----------|----------|-----------|--------|-----------|-----------|
| RBM2974100U | 20 mm    | #6       | 20M       | 64 mm  | 70 mm     | 36 mm     |
| RBM2974125X | 20 mm    | #6       | 20M       | 64 mm  | 70 mm     | 39 mm     |
| RBM2870100A | 22 mm    | #7       |           | 64 mm  | 70 mm     | 42 mm     |
| RBM2886112C | 25 mm    | #8       | 25M       | 64 mm  | 70 mm     | 49 mm     |
| RBM2886150D | 25 mm    | #8       | 25M       | 64 mm  | 70 mm     | 55 mm     |

| 物料号         | 钢筋尺寸, 公制 | 钢筋尺寸, 美国 | 钢筋尺寸, 加拿大 | 高度 (H) | 直径 1 (Ø1) | 直径 2 (Ø2) |
|-------------|----------|----------|-----------|--------|-----------|-----------|
| RBM2748100D | 28 mm    | #9       | 30M       | 64 mm  | 70 mm     | 55 mm     |
| RBM275075E  | 32 mm    | #10      |           | 64 mm  | 70 mm     | 58 mm     |
| RBM2767100E | 28 mm    | #9       | 30M       | 64 mm  | 70 mm     | 58 mm     |
| RBM266785F  | 36 mm    | #11      | 35M       | 64 mm  | 76 mm     | 65 mm     |
| RBM2669100H | 43 mm    | #14      | 45M       | 64 mm  | 86 mm     | 74 mm     |
| RBM2669125J | 43 mm    | #14      | 45M       | 64 mm  | 86 mm     | 77 mm     |
| RBM266975G  | 43 mm    | #14      | 45M       | 64 mm  | 86 mm     | 76 mm     |
| RBM2671100M | 57 mm    | #18      | 55M       | 64 mm  | 111 mm    | 96 mm     |
| RBM2671125N | 57 mm    | #18      | 55M       | 64 mm  | 111 mm    | 99 mm     |
| RBM267150K  | 57 mm    | #18      | 55M       | 64 mm  | 111 mm    | 87 mm     |
| RBM267156K  | 57 mm    | #18      | 55M       | 64 mm  | 111 mm    | 87 mm     |
| RBM267885K  | 43 mm    | #14      | 45M       | 64 mm  | 102 mm    | 87 mm     |
| RBM2687126G | 36 mm    | #11      | 35M       | 64 mm  | 86 mm     | 71 mm     |
| RBM2750125F | 32 mm    | #10      |           | 64 mm  | 76 mm     | 65 mm     |
| RBM2759K    | 36 mm    | #11      | 35M       | 64 mm  | 102 mm    | 87 mm     |


其他产品详情

Diameter 2 is the mating surface for the outside diameter of the appropriate sleeve.

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

图

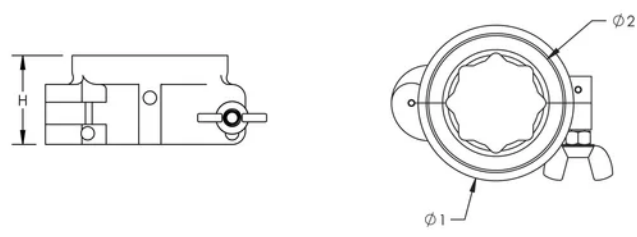

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

| 北美              | 欧洲              | 欧洲             | 亚太地区                 |
|-----------------|-----------------|----------------|----------------------|
| +1.800.753.9221 | 荷兰：             | 德国：            | 上海：                  |
| ，按 1 转客户服务      | +31 800-0200135 | 800 1890272    | + 86 21 2412 1618/19 |
| ，按 2 转技术支持      | 法国：             | 其他国家/地区：       | 悉尼：                  |
|                 | +33 800 901 793 | +31 13 5835404 | +61 2 9751 8500      |



我们强大的品牌组合：

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE