

# Horizontal Pouring Basin, Side Fill, 45°, Extended, Right Hand



Angular extended side fill horizontal pouring basins are used when interferences of the structure will not allow top filling of the sleeve and the interferences are directly next to the tap hole in the sleeve.

## 功能

Made from heat-resistant graphite

Durable, re-usable and long lasting

Designed for use with T-Series and B-Series horizontal side fill sleeves

## 技术参数

Table 1/2

| 物料号       | 材料 | 直径 (Ø) | 长度 1 (L1) | 长度 2 (L2) | 宽度 (W) | 高度 [1] (H1) |
|-----------|----|--------|-----------|-----------|--------|-------------|
| WS2482RHD | 石墨 | 54 mm  | 470 mm    | 97 mm     | 76 mm  | 203mm       |

Table 2/2

| 物料号       | 高度 [2] (H2) | 角度 (a) |
|-----------|-------------|--------|
| WS2482RHD | 89mm        | 45 °   |


其他产品详情

RBWS2482 pouring basins require one RBW350 and one RBW664 pouring basin frame and one RBS5000 bolt retainer (sold separately).

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

图

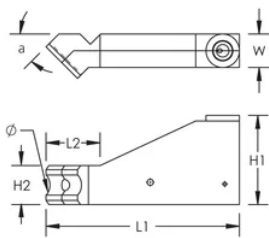

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

| 北美              | 欧洲              | 欧洲             | 亚太地区                 |
|-----------------|-----------------|----------------|----------------------|
| +1.800.753.9221 | 荷兰：             | 德国：            | 上海：                  |
| ，按 1 转客户服务      | +31 800-0200135 | 800 1890272    | + 86 21 2412 1618/19 |
| ，按 2 转技术支持      | 法国：             | 其他国家/地区：       | 悉尼：                  |
|                 | +33 800 901 793 | +31 13 5835404 | +61 2 9751 8500      |



我们强大的品牌组合：

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE