

Horizontal Pouring Basin, Side Fill, Extended



Extended side fill horizontal pouring basins are used when interferences of the structure will not allow top filling of the sleeve and the interferences are directly next to the tap hole in the sleeve.

功能

Made from heat-resistant graphite

Durable, re-usable and long lasting

Designed for use with T-Series and B-Series horizontal side fill sleeves

技术参数

材料: 石墨

Table 1/1

物料号	直径 (Ø)	长度 1 (L1)	长度 2 (L2)	宽度 (W)	高度 [1] (H1)	高度 [2] (H2)
RBHSA9750X	38 mm	248 mm	38 mm	76 mm	127mm	76mm
RBHSB10560X	38 mm	267 mm	38 mm	76 mm	152mm	76mm
RBHSB12065X	38 mm	305 mm	38 mm	76 mm	165mm	76mm
RBHSA9050D	54 mm	229 mm	38 mm	76 mm	127mm	76mm

物料号	直径 (Ø)	长度 1 (L1)	长度 2 (L2)	宽度 (W)	高度 [1] (H1)	高度 [2] (H2)
RBHSA9050F	64 mm	229 mm	38 mm	76 mm	127mm	76mm
RBHSA9560M	95 mm	241 mm	38 mm	76 mm	152mm	76mm
RBHSB12065C	48 mm	305 mm	38 mm	76 mm	165mm	76mm
RBHSB12065F	64 mm	305 mm	38 mm	76 mm	165mm	76mm
RBHSB12065J	76 mm	305 mm	38 mm	76 mm	165mm	76mm
RBHSB12065M	95 mm	305 mm	38 mm	76 mm	165mm	76mm
RBHSB14065F	64 mm	356 mm	38 mm	76 mm	165mm	76mm
RBHSB14065J	76 mm	356 mm	38 mm	76 mm	165mm	76mm
RBHSB14070D	54 mm	356 mm	38 mm	76 mm	178mm	76mm
RBHSB14075M	95 mm	356 mm	38 mm	76 mm	191mm	76mm
RBHSB16070F	64 mm	406 mm	38 mm	76 mm	178mm	76mm
RBHSB17070C	48 mm	432 mm	38 mm	76 mm	178mm	76mm
RBHSB177550 M	95 mm	451 mm	38 mm	76 mm	127mm	76mm
RBHSC23010M	95 mm	584 mm	38 mm	76 mm	254mm	76mm
RBHSC23075M	95 mm	584 mm	38 mm	76 mm	191mm	76mm
RBHSC30070D	54 mm	762 mm	38 mm	76 mm	191mm	76mm


其他产品详情

RBHSA pouring basins require one RBW332 pouring basin frame and two RBS5000 bolt retainers. RBHSB pouring basins require one RBW3321 pouring basin frame and one RBS5000 bolt retainer. RBHSC pouring basins require one RBW3322 pouring basin frame and one RBS5000 bolt retainer (all sold separately).

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

图

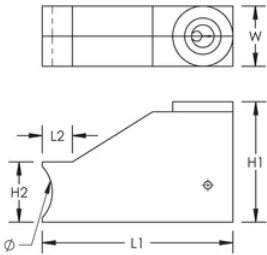

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE