

Horizontal Pouring Basin, Top Fill, Standard



Standard horizontal pouring basins should be used whenever the clearances of the structure allow. The compact size of the standard pouring basins help ensure the best possible flow of filler material.

功能

Made from heat-resistant graphite

Durable, re-usable and long lasting

Designed for use with T-Series and B-Series horizontal top fill sleeves

技术参数

材料: 石墨

Table 1/1

物料号	直径 (Ø)	长度 (L)	宽度 (W)	高度 (H)
RBWS1467D	54 mm	86mm	89 mm	102 mm
RBWS1467F	64 mm	86mm	89 mm	102 mm
RBWS1467M	95 mm	86mm	89 mm	102 mm
RBWS1467U	35 mm	86mm	89 mm	102 mm
RBWS1467X	38 mm	86mm	89 mm	102 mm

物料号	直径 (Ø)	长度 (L)	宽度 (W)	高度 (H)
RBWS1467E	57 mm	86mm	89 mm	102 mm
RBWS1467G	70 mm	86mm	89 mm	102 mm
RBWS1467C	48 mm	86mm	89 mm	102 mm
RBWS1467A	41 mm	86mm	89 mm	102 mm
RBWS1467K	86 mm	86mm	89 mm	102 mm
RBWS1467H	73 mm	86mm	89 mm	102 mm
RBWS1467J	76 mm	86mm	89 mm	102 mm


其他产品详情

RBWS1467 pouring basins require one RBW167 pouring basin frame (sold separately).

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

图

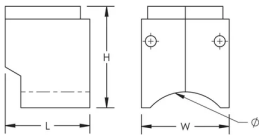

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE