


P13 Position Coupler, Plain, Worldwide Design

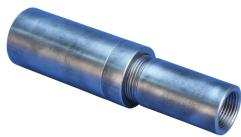

认证



功能

Designed to splice the same diameter bars

Designed to splice two curved, bent or straight bars, when neither bar can be rotated and where the ongoing bar is NOT free to move in its axial direction

Adjustability in the female end of the coupler allows the coupler to extend out to meet the taper-threaded reinforcing bar

技术参数

完成:	普通
联轴器调整:	标准
材料:	钢

Table 1/2

物料号	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	直径 (Ø)	长度 1 (L1)	长度 2 (L2)
EL10P13LN	10 mm	#3		25 mm	120 mm	155 mm
EL12P13LN	12 mm	#4	10M	25 mm	124 mm	159 mm
EL14P13LN	14 mm			25 mm	134 mm	172 mm
EL16P13LN	16 mm	#5	15M	30 mm	144 mm	186 mm
EL18P13LN	18 mm			35 mm	162 mm	208 mm
EL20P13LN	20 mm	#6	20M	35 mm	199 mm	260 mm
EL22P13LN	22 mm	#7		40 mm	210 mm	273 mm
EL25P13LN	25 mm	#8	25M	45 mm	221 mm	287 mm
EL28P13LN	28 mm	#9	30M	50 mm	229 mm	298 mm
EL32P13LN	32 mm	#10		60 mm	249 mm	321 mm
EL30P13LN	30 mm			55 mm	262 mm	340 mm
EL36P13LN	36 mm	#11	35M	65 mm	271 mm	349 mm
EL38P13LN	38 mm	#12		70 mm	277 mm	357 mm
EL34P13LN	34 mm			60 mm	280 mm	362 mm
EL40P13LN	40 mm			70 mm	290 mm	374 mm

物料号	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	直径 (Ø)	长度 1 (L1)	长度 2 (L2)
EL43TP13LN	43 mm	#14	45M	75 mm	341 mm	433 mm
EL50TP13LN	50 mm			90 mm	358 mm	454 mm
EL57TP13LN	57 mm	#18	55M	100 mm	404 mm	513 mm

Table 2/2						
物料号	杆深 (BD)	杆间隙 1 (BG1)	杆间隙 2 (BG2)	联轴器主体 (CB)	单位重量	认证
EL10P13LN	18mm	84mm	119mm	70mm	0.36 kg	RISE, ACRS, nVent LENTON EPD - Product Specific, ITB, DIBt, TZUS, AFCAB, Kontrollrådet
EL12P13LN	19mm	86mm	121mm	75mm	0.36 kg	KOMO, ITB, Kontrollrådet, nVent LENTON EPD - Product Specific, RISE, CARES, TZUS, AFCAB, DIBt, Kontrollrådet, ACRS
EL14P13LN	21mm	92mm	130mm	82mm	0.37 kg	AFCAB, Kontrollrådet, KOMO, TZUS, CARES, Kontrollrådet, nVent LENTON EPD - Product Specific, RISE, ACRS, DIBt, ITB

物料号	杆深 (BD)	杆间隙 1 (BG1)	杆间隙 2 (BG2)	联轴器主体(CB)	单位重量	认证
EL16P13LN	24mm	96mm	138mm	89mm	0.59 kg	ITB, KOMO, CARES, TZUS, ACRS, AFCAB, Kontrollrådet, Kontrollrådet, nVent LENTON EPD - Product Specific, RISE, DIBt
EL18P13LN	29mm	104mm	150mm	101mm	0.85 kg	nVent LENTON EPD - Product Specific, ITB, ACRS, TZUS
EL20P13LN	35mm	129mm	190mm	126mm	1.09 kg	ITB, ACRS, KOMO, CARES, AFCAB, TZUS, Kontrollrådet, nVent LENTON EPD - Product Specific, RISE, Kontrollrådet, DIBt
EL22P13LN	37mm	136mm	199mm	132mm	1.55 kg	TZUS, ITB, nVent LENTON EPD - Product Specific, ACRS
EL25P13LN	40mm	140mm	207mm	140mm	1.94 kg	DIBt, ITB, Kontrollrådet, AFCAB, TZUS, RISE, CARES, nVent LENTON EPD - Product Specific, ACRS, Kontrollrådet, KOMO


物料号	杆深 (BD)	杆间隙 1 (BG1)	杆间隙 2 (BG2)	联轴器主体(CB)	单位重量	认证
EL28P13LN	42mm	145mm	214mm	147mm	2.53 kg	DIBt, TZUS, ACRS, nVent LENTON EPD - Product Specific, ITB, KOMO
EL32P13LN	45mm	159mm	231mm	156mm	3.96 kg	Kontrollrådet, ITB, AFCAB, TZUS, DIBt, KOMO, nVent LENTON EPD - Product Specific, RISE, Kontrollrådet, CARES, ACRS
EL30P13LN	52mm	158mm	236mm	169mm	3.35 kg	ACRS, nVent LENTON EPD - Product Specific
EL36P13LN	52mm	167mm	245mm	172mm	5.01 kg	TZUS, ACRS, nVent LENTON EPD - Product Specific
EL38P13LN	53mm	171mm	251mm	175mm	6.05 kg	ACRS, nVent LENTON EPD - Product Specific
EL34P13LN	55mm	170mm	252mm	177mm	4.28 kg	ACRS, nVent LENTON EPD - Product Specific
EL40P13LN	57mm	176mm	260mm	184mm	6.18 kg	AFCAB, TZUS, RISE, Kontrollrådet, ITB, nVent LENTON EPD - Product Specific, ACRS, DIBt, CARES

物料号	杆深 (BD)	杆间隙 1 (BG1)	杆间隙 2 (BG2)	联轴器主体(CB)	单位重量	认证
EL43TP13LN	66mm	209mm	301mm	214mm	8.24 kg	nVent LENTON EPD - Product Specific
EL50TP13LN	70mm	218mm	314mm	224mm	11.97 kg	nVent LENTON EPD - Product Specific, CARES
EL57TP13LN	83mm	238mm	347mm	256mm	17.11 kg	nVent LENTON EPD - Product Specific

其他产品详情

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

图

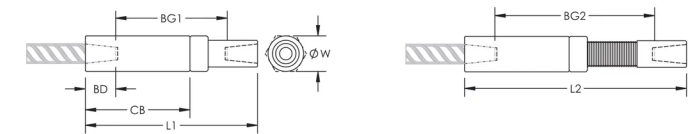

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE