

T-Series Horizontal Fixed Angle Splice Kit, Top Fill, 45-75°



T-Series splice kits contain the following: Sleeve, filler material kit (filler material, packing, pouring basin ceramic insert and disk, pouring basin ceramic guide tube), pouring basin and pouring basin crucible. Splice kits are ordered based on the quantity of splices needed. Sleeves and filler material kits are one-time use parts. Pouring basins and crucibles are prorated based on their anticipated life. Ordering splice kits simplifies ordering, reduces order errors and helps ensure proper sizing of components. Kits can be ordered with longer (extended) sleeves for use when the reinforcing steel deformation pattern or spacing does not meet the minimum product specifications.

功能

Simplifies ordering

Used to splice the same diameter bars

技术参数

套管： 标准长度

Table 1/2

物料号	角度 (a)	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	长度 1 (L1)	长度 2 (L2)
RBT189175H	75 °	57 mm	#18	55M	129 mm	390 mm
RBT189145H	45 °	57 mm	#18	55M	180 mm	268 mm

Table 2/2

物料号	高度 [1] (H1)	高度 [2] (H2)	直径 (Ø)
-----	-------------	-------------	--------

RBT189175H	576mm	253mm	178 mm
RBT189145H	601mm	225mm	178 mm

其他产品详情


Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

All dimensions are for reference only.

Components can also be purchased separately: (1) Sleeve, (2) Filler Material Kit (filler material, packing, pouring basin ceramic insert and disk, pouring basin ceramic guide tube), (3) Pouring Basin, and (4) Pouring Basin Crucible.

Splice Kit Components							
Splice Kit	Filler Material	Packing (2 Required)	Pouring Basin Ceramic Insert and Disk	Pouring Basin Ceramic Guide Tube	Sleeve	Pouring Basin	Pouring Basin Crucible
RBT189145H	RBF270	RBS354720 RBS35479	RBS5037	RBS5039	RBT1891HA	RBWS1537M	RBWS22777
RBT189175H	RBF270	RBS354720 RBS35479	RBS5037	RBS5039	RBT1891A	RBWS2224M	RBWS22777

图

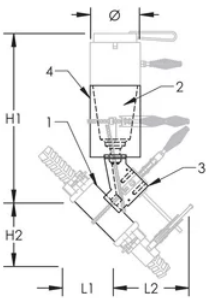

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE